


Obria™ Accessory

Cat. No(s): MEC15062/63XX MY MEC17060/61/64/65XX MY
 "XX" = Color / finishes: WH SL CH BL RG
 "MY" = Malaysia

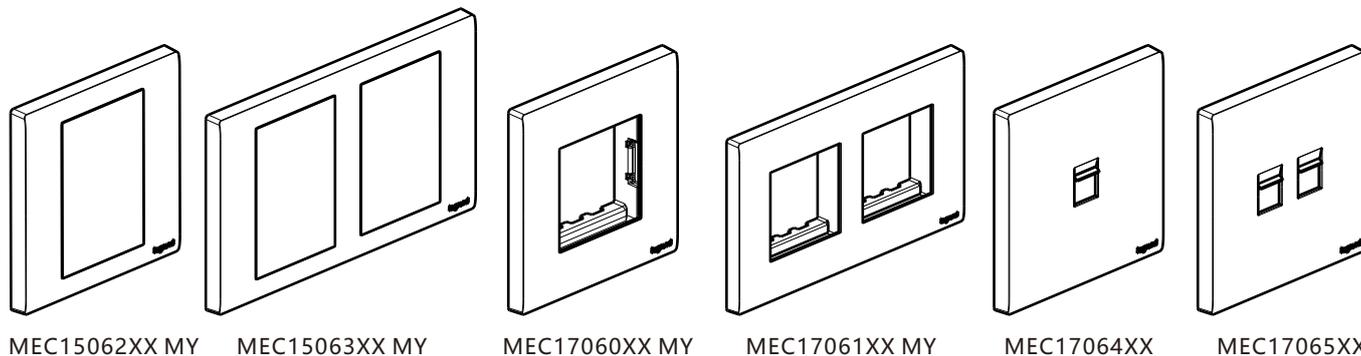

1. USE

Decoration and reserve for future use.
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE


Designation	Cat. No.
1G BLANKING PLATE	MEC15062XX MY
2G BLANKING PLATE	MEC15063XX MY
1G 2 MODULES ARTEOR ADAPTOR	MEC17060XX MY
2G 2 MODULES ARTEOR ADAPTORS	MEC17061XX MY
KEYSTONE ADAPTER DOUBLE	MEC17064XX
KEYSTONE ADAPTER DOUBLE	MEC17065XX

Colours

-Matt colors finishes

WH: Matt White
 SL: Dark silver
 CH: Champagne
 BL: Matt Black
 RG: Rose gold

3. DIMENSIONS (mm)

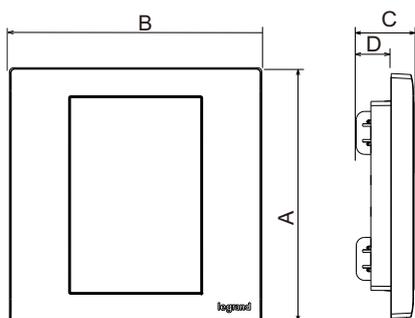

3. DIMENSIONS (mm)(Continued)

References	A	B	C	D
MEC15062XX MY	87.4	86	20.5	12.3
MEC15063XX MY	87.4	146	20.5	12.3
MEC17060XX MY	87.4	86	15	7.1
MEC17061XX MY	87.4	146	15	7.1
MEC17064XX MY	87.4	86	16.2	8.3
MEC17065XX MY	87.4	86	16.2	8.3

4. TECHNICAL CHARACTERISTICS

4.1 Material characteristics

Plate: PC
 Frame: PC
 Other: PC
 Self-extinguishing:
 + 650° C / 30 s

4.2 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

4.3 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

5. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene

6. CONFORMITY - APPROVALS

Comply with installation and manufacturing standards.
 Refer to e-catalogue.
 Conform to IEC 60670-1