



Obria™ RJ11 socket

Cat. No(s): MEC42017/70XX MY
 "XX" = Color / finishes: WH SL CH BL RG
 "MY" = Malaysia

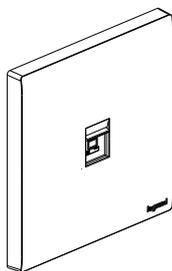

MEC42017XX MY

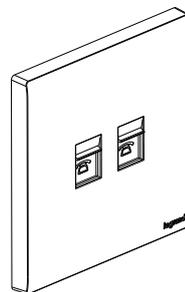

MEC42070XX MY

1. USE

Telephone socket outlet with shutters for the transmission telephone signals.
 (Supplied with M3.5 screws for BS boxes. Flush mounting or Surface mounting.)

2. RANGE


Designation	Cat. No.
RJ 11 SOCKET	MEC42017XX MY
DOUBLE RJ11 TELEPHONE SOCKET	MEC42070XX MY

Colours

-Matt colors finishes

WH: Matt White
 SL: Dark silver
 CH: Champagne
 BL: Matt Black
 RG: Rose gold

3. DIMENSIONS (mm)

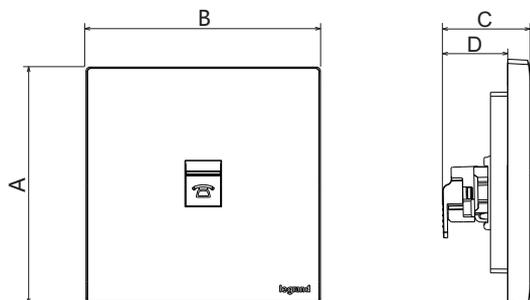

References	A	B	C	D
MEC42017XX MY MEC42070XX MY	87.4	86	31.5	22.8

Box depth ≥ 40 mm

4. TECHNICAL CHARACTERISTICS

4.1 Material characteristics

Shutter: PC
 Plate: PC
 Frame: PC
 Self-extinguishing:
 + 850° C / 30 s for insulating parts holding live parts in place
 + 650° C / 30 s for other parts made of insulating materials

4.2 Electrical characteristic

-Contact blades gold plated on nickel(gold thickness: 0.125µm)

4.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

4.4 Mechanical characteristics

Impact test: IK04
 Protection against liquids: IP20

5. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene