



Obria™ RJ45 SOCKET

Cat. No(s): MEC43018/68XX MY
 "XX" = Color / finishes: WH SL CH BL RG
 "MY" = Malaysia

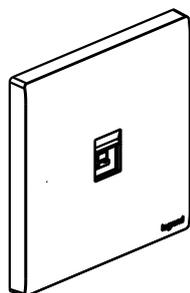

MEC43018XX MY

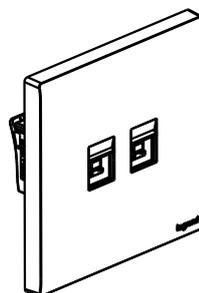

MEC43068XX MY

1. USE

Computer socket outlet for the transmission of data. With shutters.
 (Supplied with M3.5 screws for BS boxes. Flush mounting or surface mounting.)

2. RANGE


Designation	Cat. No.
RJ 45 CAT 6 SOCKET	MEC43018XX MY
RJ 45 DOUBLE CAT 6 UTP	MEC43068XX MY

Colours

-Matt colors finishes

- WH: Matt White
- SL: Dark silver
- CH: Champagne
- BL: Matt Black
- RG: Rose gold

3. DIMENSIONS (mm)

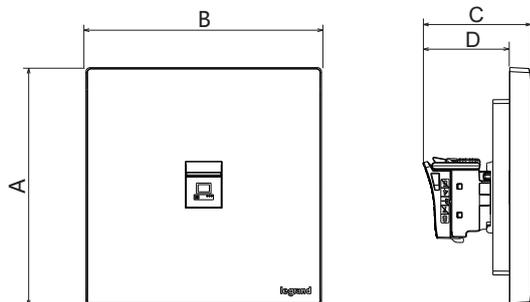

References	A	B	C	D
MEC43018XX MY	87.4	86	39.9	31.3
MEC43068XX MY				

Minimum depth of the box > 40 mm

4. TECHNICAL CHARACTERISTICS

4.1 Material characteristics

- Shutter: PC
- Plate: PC
- Frame: PC
- Base: PC
- Self-extinguishing:
 - + 850° C / 30 s for insulating parts holding live parts in place
 - + 650° C / 30 s for other parts made of insulating materials

4.2 Electrical characteristics

- Breakdown Voltage $\geq 1000V$
- Contact resistance $\leq 20m\Omega$
- Insulation resistance $\geq 500m\Omega$ at DC 100V
- Contact blades gold plated on nickel (gold thickness: 0.75µm)

4.3 Climatic characteristics

- Storage temperatures: -10°C to +70°C
- Operating temperatures: -5°C to +35°C

4.4 Mechanical characteristics

- Impact test: IK04
- Protection against solids & liquids: IP20

5. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene.