


**Céline™**  
**Smart Gateway**

**Cat. No(s): CB0443B - CT0443B - CN0443B**

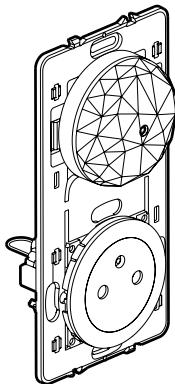

**1. USE**


This pack enables you to create a connected installation in your home. It can be used to control lighting, roller shutters and electrical equipment plugged into connected sockets:

- using your smartphone and the Home + Control app
- using voice assistants
- from wireless commands, with or without battery

**Control socket (Zigbee relay/WiFi)**

Installation in 1-gang box 40 mm deep (minimum). Screw fixing, (claw fixing possible, sold separately).

**2. DIMMENSIONS (mm)**

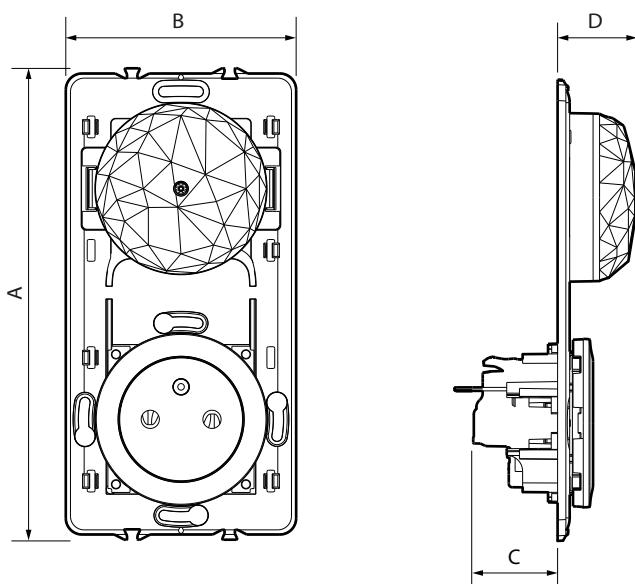


<b>A</b>	<b>B</b>	<b>C</b>	<b>D</b>
145	71	27	25

**3. RANGE**

<b>Description</b>	<b>White</b>	<b>Titanium</b>	<b>Black</b>
Control pack with socket : Supplied with site protection cover. Equipped with a configuration button used to launch the configuration process or to return to factory settings. To be equipped with finishing plate	CB0443B	CT0443B	CN0443B

**4. OPERATION**

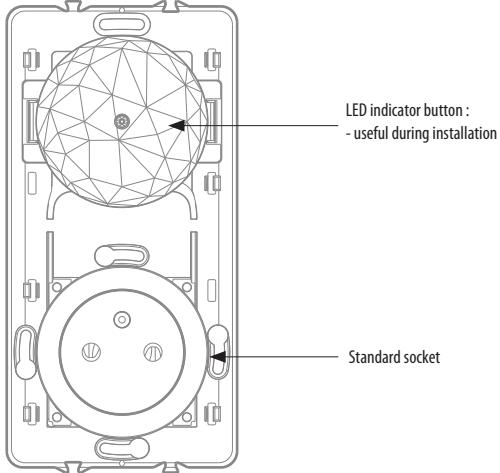

## **5. CONNECTION**

Terminal type: automatic  
Terminal capacity: 2 x 2.5 mm<sup>2</sup>  
Stripping length: 11 mm

## **6. TECHNICAL CHARACTERISTICS**

### **■ 6.1 Mechanical characteristics**

Protection against impacts: IK 04  
Protection against solid bodies and/or liquids: IP 20

### **■ 6.2 Material characteristics**

Cover plate: PC  
Mechanism casing: PC  
Support: PC GF 20%  
UV-resistant  
Self-extinguishing:  
850°C/30 s for insulating components holding live parts in place.  
650°C/30 s for other insulating components.

### **■ 6.3 Electrical characteristics**

Voltage: 230 V~  
Current: 16 A  
Power: 3680 W max.  
Frequency: 50/60 Hz  
Standby consumption: 7 mA

#### **Wi-Fi radio technology:** 2.4 GHz 802.11 b/g/n

Supported security: WEP/WPA/WPA2-personal (TKIP and AES)  
Maximum range depends on the Wi-Fi access point. We recommend installing the Control Socket in the same room and close to the Wi-Fi access point.

#### **Zigbee radio technology:** frequency: 2.4 GHz to 2.4835 GHz

Zigbee Range: 200 m of unobstructed space  
10 m recommended between products indoors

### **■ 6.4 Climate characteristics**

Storage temperature: 0° C to + 45° C  
Usage temperature: +5° C to + 35° C

## **7. CARE**

Clean the surface with a cloth.  
Do not use acetone, tar-removing cleaning agents or trichloroethylene.  
Resistant to the following products: Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

**Caution:** Always test before using special cleaning products.

## **9. STANDARDS AND APPROVALS**

The undersigned, LEGRAND, declares that the radio-electric equipment type (CB0443B - CN0443B - CT0443B) complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website: [www.legrand.com/ecatalogue](http://www.legrand.com/ecatalogue)