


Arteor™ Advance Fan controller monobloc

Cat. No(s): AC666MW/MB/MT

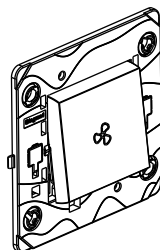

AC666MW/MB/MT


1. USE

Fan Control.
Need to be equipped with special plate.
Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.
Box depth ≥ 35 mm

2. RANGE

Description	Type	Matt White	Matt Black	Matt Titanium
1G 6A 3 POLES FAN CONTROLLER	1-gang	AC666MW	AC666MB	AC666MT

3. DIMENSIONS (mm)

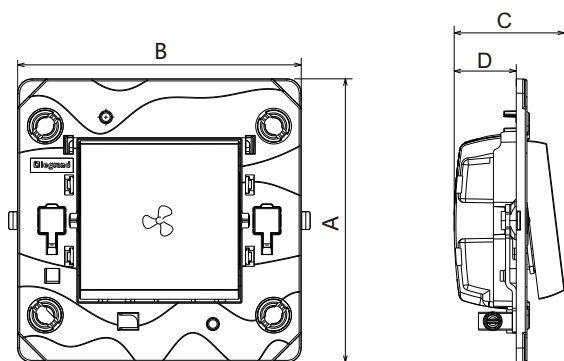

References	A	B	C	D
AC666MW/MB/MT	79.5	84.5	30.9	17.4

4. CONNECTION

Types of terminals: with screws
Terminal capacity: 5 × 1.5 mm²
3 × 2.5 mm²
2 × 4 mm²
1 × 6 mm²
Stripping length: 8 mm
Screwdriver size: 4 mm flat blade

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Impact test: IK04
Protection against solids & liquids: IP20

■ 5.2 Material characteristics

Rocker: PC
Frame: PC
Base: PP
Self-extinguishing:
+ 850° C / 30 s for insulating parts holding live parts in place
+ 650° C / 30 s for other parts made of insulating materials

■ 5.3 Electrical characteristics

Voltage: 250V~
Current: 6A
Frequency: 50/60Hz

■ 5.4 Climatic characteristics

Usage temperature: -5°C to +35°C
Storage temperature: -10°C to +70°C

6. CARE

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products: Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using special cleaning products.

7. CONFORMITY - APPROVALS

Conform to IEC 60669-1 standard