



Arteor™ Advance Fused Connection Unit

Cat. No(s): AC620MW/MB/MT/CH/DB/RS - AC621MW/MB/MT/CH/DB/RS
AC622MW/MB/MT/CH/DB/RS

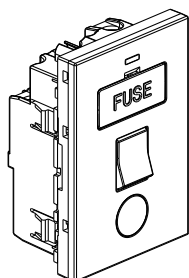

AC621MW/MB/MT/CH/DB/RS
AC622MW/MB/MT/CH/DB/RS

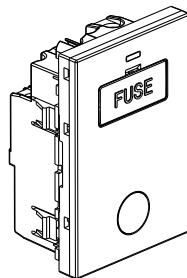

AC620MW/MB/MT/CH/DB/RS


1. USE

Used for overload protection.

2. RANGE

Description	Type	Matt White	Matt Black	Matt Titanium	Champagne	Dark Bronze	Rose
13A UNSW FCU +CORD OUTLET	3M	AC620MW	AC620MB	AC620MT	AC620CH	AC620DB	AC620RS
13A SWITCHED FCU +CORD OUTLET	3M	AC621MW	AC621MB	AC621MT	AC621CH	AC621DB	AC621RS
13A SWITCHED FCU +CORD OUTLET +LED	3M	AC622MW	AC622MB	AC622MT	AC622CH	AC622DB	AC622RS

3. DIMENSIONS (mm)

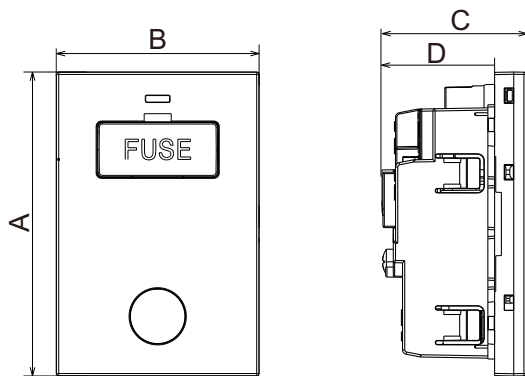

References	A	B	C	D
AC620MW/MB/MT/CH/DB/RS	67.5	45.1	32	23.5
AC621MW/MB/MT/CH/DB/RS	67.5	45.1	34.6	23.5
AC622MW/MB/MT/CH/DB/RS	67.5	45.1	34.6	23.5

4. CONNECTION

Types of terminals: with screws

Terminal capacity: 5 × 1.5 mm²

3 × 2.5 mm²

2 × 4 mm²

1 × 6 mm²

Stripping length: 12 mm

Screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Impact test: IK04

Protection against solids & liquids: IP20

■ 5.2 Material characteristics

Rocker: PC

Cover: PC

Base: PC

Self-extinguishing:

+ 850° C / 30 s for insulating parts holding live parts in place

+ 650° C / 30 s for other parts made of insulating materials

■ 5.3 Electrical characteristics

Voltage: 250V~

Current: 13A

■ 5.4 Climatic characteristics

Usage temperature: -5°C to +35°C

Storage temperature: -10°C to +70°C

6. CARE

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products: Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using special cleaning products.

7. CONFORMITY - APPROVALS

Conform to BS1363-4 standard