


Arteor™
2 New RSA socket outlet

Cat. No(s): 5 700 90 5 710 92 5 720 66

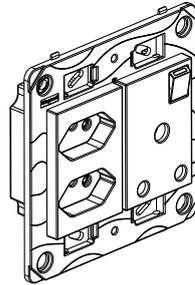

5 700 90
 5 710 92
 5 720 66


1. USE

2 new RSA socket outlets and 1 old RSA switched socket outlet.
 Need to be equipped with special plate.
 Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.
 Box depth ≥ 35 mm

2. RANGE

Description	Type	Soft Alu	Champagne	White
Twin Socket (2 New + 1 South African Socket) Pre-wired	One gang	5 700 90	5 710 92	5 720 66

3. DIMENSIONS (mm)

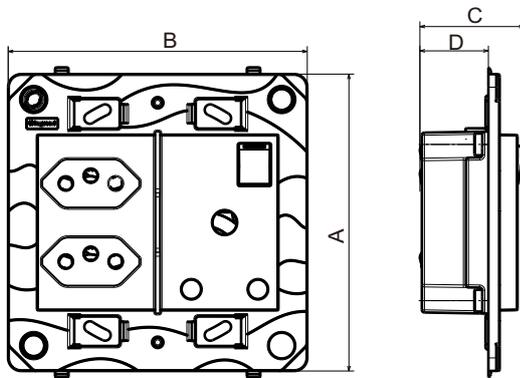

References	A	B	C	D
5 700 90 5 710 92 5 720 66	114	114	39.7	26.1

4. CONNECTION

Types of terminals: with screws
 Terminal capacity: 5 × 1.5 mm²
 3 × 2.5 mm²
 2 × 4 mm²

Stripping length: 8 mm
 Screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

5.2 Material characteristics

Rocker: PC
 Frame: PC
 Base: PC
 Self-extinguishing:
 + 850° C / 30 s for insulating parts holding live parts in place
 + 650° C / 30 s for other parts made of insulating materials

5.3 Electrical characteristics

Voltage: 250V~
 Current: 16AX
 Max. power for self-ballasted lamps: 100W
 Frequency: 50/60Hz

5.4 Climatic characteristics

Usage temperature: -5°C to +35°C
 Storage temperature: -10°C to +70°C

6. CARE

Clean the surface with a cloth.
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products: Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using special cleaning products.

7. CONFORMITY - APPROVALS

Compliant with installation and manufacturing standards, see e-catalogue.