 


Arteor™ Advance Shaver sockets

Cat. No(s): AC360MW/MB/MT/CH/DB/RS - AC361MW/MB/MT/CH/DB/RS



AC360MW/MB/MT/CH/DB/RS
AC361MW/MB/MT/CH/DB/RS

1. USE

Device for the supply of electric shavers requiring either a 230V or 120V supply and having a power consumption not exceeding 20VA. Accepts the following types of plug: BS, Euro, US, Australian and Chinese.

Need to be equipped with special plate.


Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.

Box depth ≥ 35 mm

2. RANGE

Description	Type	Matt White	Matt Black	Matt Titanium	Champagne	Dark Bronze	Rose
SHAVER SOCKET 230V/120-230	2-gang	AC360MW	AC360MB	AC360MT	AC360CH	AC360DB	AC360RS
SHAVER SOCKET 230V/120-230 EARTH	2-gang	AC361MW	AC361MB	AC361MT	AC361CH	AC361DB	AC361RS

3. DIMENSIONS (mm)

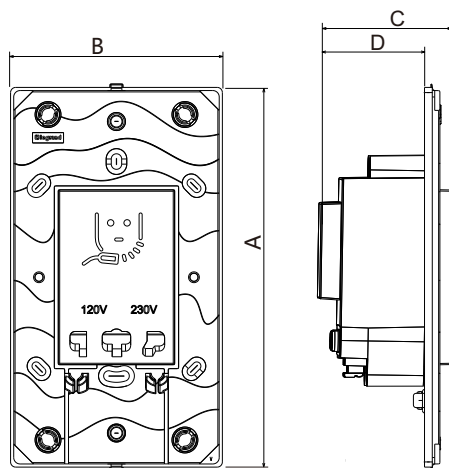

References	A	B	C	D
AC360MW/MB/MT/CH/DB/RS	149.6	82	51.9	40.9
AC361MW/MB/MT/CH/DB/RS	149.6	82	51.9	40.9

4. CONNECTION

Types of terminals: auto terminal

Terminal capacity: 2 X 1.5 mm²

2 X 2.5 mm²

Stripping length: 13 mm

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Impact test: IK04

Protection against solids & liquids: IP24

■ 5.2 Material characteristics

Frame cover: PC

Base: PC

Self-extinguishing:

+ 850° C / 30 s for insulating parts holding live parts in place

+ 650° C / 30 s for other parts made of insulating materials

■ 5.3 Electrical characteristics

Voltage:

■ Supply: 230V~

■ Output: 230/120V~

■ 5.4 Climatic characteristics

Usage temperature: -5°C to +35°C

Storage temperature: -10°C to +70°C

6. CARE

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products: Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using special cleaning products.

7. STANDARDS AND APPROVALS

Conform to IEC 61558-1 standard