


Arteor™ Advance Melody chime

Cat. No(s): AC617MW/MB

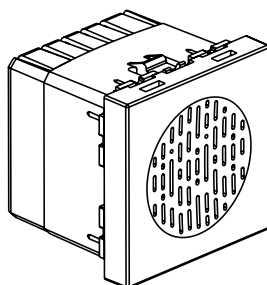


1. USAGE

Hotel equipment 1 melody.
Wiring devices compatible with push-button.
Mechanisms supplied with cover.
To be equipped with support frame and finishing plate.

2. RANGE

Designation	Finishes	
	Matt White	Matt Black
1 module 1 melody	AC617MW	AC617MB

3. DIMENSIONS (mm)

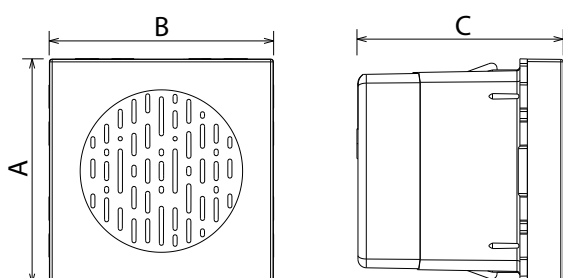

A	B	C
45.05	45.05	41.4

4. CONNECTION

Type of terminals: with screws
Terminal capacity: 1.5 mm²
Stripping length: 8 mm

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Impact tests: IK 04
Protection against solid bodies and liquids: IP 40 (mounted)
IP 20 (alone)

■ 5.2 Material characteristics

Mechanism casing : PC
Cover: ABS
Halogen-free
UV-resistant
Self-extinguishing:
850°C/30 s for insulating parts holding live parts in place.
650°C/30 s for other parts made of insulating materials.

■ 5.3 Electrical characteristics

Voltage: 250V~
Current: 65 mA
Tone level: 73dB at 1 m

■ 5.4 Climate characteristics

Storage temperature: - 10° C to + 70° C
Usage temperature: 0° C to + 35° C

6. CLEANING

Surface cleaning with a cloth.
Do not use: acetone, tar remover, trichloroethylene.
Resistance to the following agents:
Hexane, methylated spirits, soapy water, diluted ammonia, pure bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using other special cleaning products

7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.
Refer to e-catalogue.