


Arteor™ Advance Buzzer

Cat. No(s): AC615MW/MB/MT
AC616MW/MB

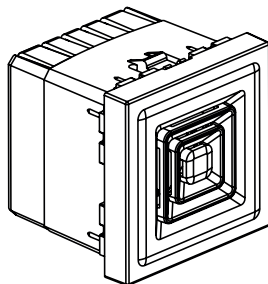


1. USAGE

Hotel equipment buzzer.
Mechanisms supplied with cover.
To be equipped with support frame and finishing plate.

2. RANGE

Designation	Finishes		
	Matt White	Matt Black	Matt Titanium
1 module Buzzer	AC615MW	AC615MB	AC615MT
2 modules Buzzer	AC616MW	AC616MB	-

3. DIMENSIONS (mm)

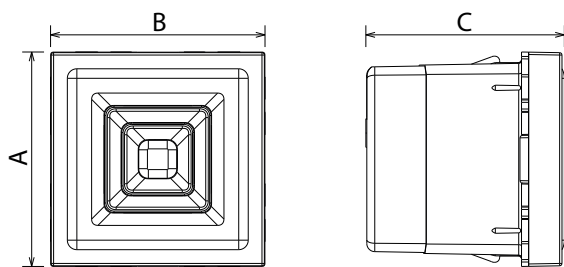

Cat. Nos	A	B	C
AC615MW/MB/MT	45.05	22.5	42.7
AC616MW/MB	45.05	45.05	41.7

4. CONNECTION

Type of terminals: with screws
Terminal capacity: 1.5 mm²
Stripping length: 8 mm

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Impact tests: IK 04
Protection against solid bodies and liquids: IP 40 (mounted)
IP 20 (alone)

■ 5.2 Material characteristics

Mechanism casing : PC
Cover: ABS

Halogen-free

UV-resistant

Self-extinguishing:

850°C/30 s for insulating parts holding live parts in place.
650°C/30 s for other parts made of insulating materials.

■ 5.3 Electrical characteristics

Voltage: 250V~
Max run ON: 0.5 h
Tone level: >65dB at 1 m

■ 5.4 Climate characteristics

Storage temperature: - 10° C to + 70° C
Usage temperature: 0° C to + 35° C

6. CLEANING

Surface cleaning with a cloth.
Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents:

Hexane, methylated spirits, soapy water, diluted ammonia, pure bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using other special cleaning products

7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.
Refer to e-catalogue.