


Arteor™ Advance Special plates for BS Socket outlets Classic Collection

Cat. No(s): AA1100MW/MB/MT/CH/DB/RS - AA1101MW/MB/MT/CH/DB/RS
AA1102MW/MB/MT/CH/DB/RS - AA1103MW/MB/MT/CH/DB/RS - AC1109MW/MB/MT
AA1113MW/MB/MT/CH/DB/RS - AA1115MW/MB/MT/CH/DB/RS
AA1117MW/MB/MT/CH/DB/RS - AC1136MW/MB/MT/CH/DB/RS

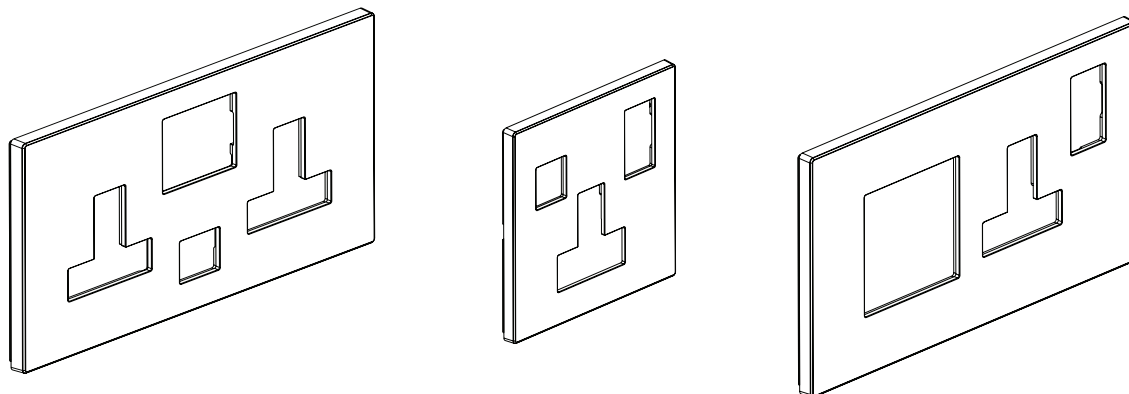

1. USE

Finishing plates.


The plates clip into notches on screw and/or claw fixings.

Protection film must be removed only once site work is fully completed.

2. RANGE

Designation	Finishes					
Classic Collection	Matt White	Matt Black	Matt Titanium	Champagne	Dark Bronze	Rose
For British Standard Socket Outlets						
For 5A/13A switched socket outlet - 1 gang	AA1100MW	AA1100MB	AA1100MT	AA1100CH	AA1100DB	AA1100RS
For 13A twin switched socket outlet - 2 gang	AA1101MW	AA1101MB	AA1101MT	AA1101CH	AA1101DB	AA1101RS
For 5A/13A unswitched socket outlet - 1 gang	AA1102MW	AA1102MB	AA1102MT	AA1102CH	AA1102DB	AA1102RS
For 5A/13A unswitched socket outlet 2 gang	AA1103MW	AA1103MB	AA1103MT	AA1103CH	AA1103DB	AA1103RS
For British Standard or Multistandard Socket Outlets with USB charger						
For single or double pole switched USB Type-A + Type-C - 1 gang	AA1113MW	AA1113MB	AA1113MT	AA1113CH	AA1113DB	AA1113RS
For single or double pole switched USB Type-A + Type-C - 2 gang	AA1115MW	AA1115MB	AA1115MT	AA1115CH	AA1115DB	AA1115RS
For switched USB Type-A + Type-C - 2 gang	AA1117MW	AA1117MB	AA1117MT	AA1117CH	AA1117DB	AA1117RS
For Cooker Unit						
For cooker unit - 2 gang	AC1109MW	AC1109MB	AC1109MT	-	-	-
For 45A DP switch or Shaver Socket						
For 3 modules 45A Double Pole switch or Shaver socket - 2 gang	AC1136MW	AC1136MB	AC1136MT	AC1136CH	AC1136DB	AC1136RS

3. DIMENSIONS (mm)

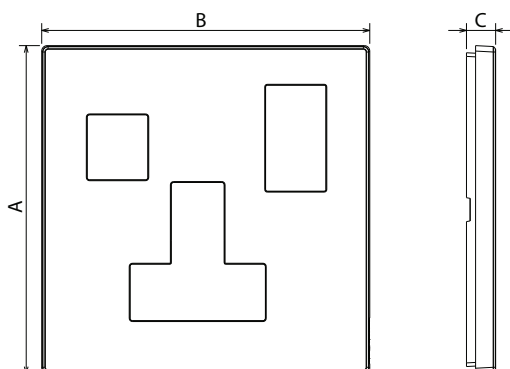

Cat. Nos	A	B	C
AA1100MW/MB/MT/CH/DB/RS AA1102MW/MB/MT/CH/DB/RS AA1113MW/MB/MT/CH/DB/RS	90	90	8
AA1101MW/MB/MT/CH/DB/RS AA1103MW/MB/MT/CH/DB/RS AC1109MW/MB/MT AA1115MW/MB/MT/CH/DB/RS AA1117MW/MB/MT/CH/DB/RS AC1136MW/MB/MT/CH/DB/RS	90	157	8

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Adjuster : PC

Plate: PC

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexan.

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach
10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.