


Arteor™ Advance Special plates for BS Socket outlets Decor Collection

Cat. No(s): AA1100FW/FB/DA/BS/BB/AB - AA1101FW/FB/DA/BS/BB/AB - AA1102FW/FB/DA/BS/BB/AB
AA1103FW/FB/DA/BS/BB/AB - AA1113FW/FB/DA/BS/BB/AB - AA1115FW/FB/DA/BS/BB/AB
AC1136FW/FB/DA/BS/BB/AB - AA1117FW/FB/DA/BS/BB/AB - AC1109FW/FB/DA/BS

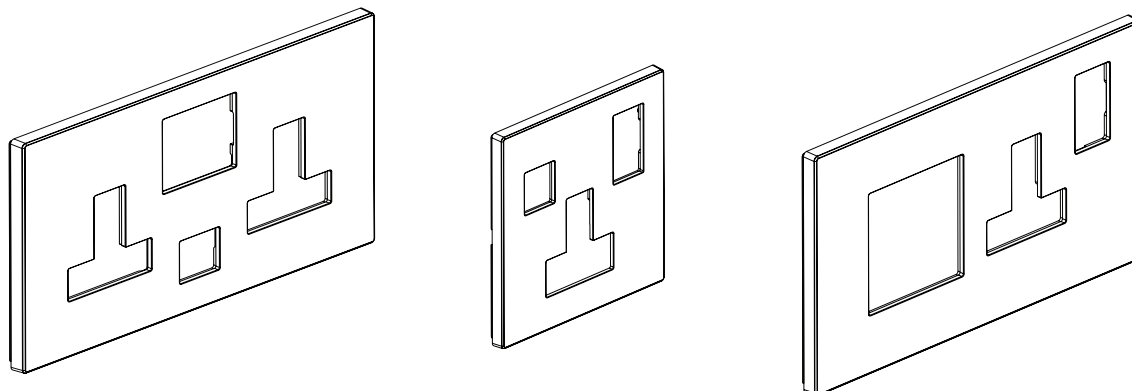

1. USE

Finishing plates.


The plates clip into notches on screw and/or claw fixings.

Protection film must be removed only once site work is fully completed.

2. RANGE

Designation Decor Collection	Finishes					
	Frosted White	Frosted Black	Dark Aluminium	Brushed Stainless Steel	Brushed Bronze	Brushed Antique Brass
For British Standard Socket Outlets						
For 5A/13A switched socket outlet - 1 gang	AA1100FW	AA1100FB	AA1100DA	AA1100BS	AA1100BB	AA1100AB
For 13A twin switched socket outlet - 2 gang	AA1101FW	AA1101FB	AA1101DA	AA1101BS	AA1101BB	AA1101AB
For 5A/13A unswitched socket outlet - 1 gang	AA1102FW	AA1102FB	AA1102DA	AA1102BS	AA1102BB	AA1102AB
For 5A/13A unswitched socket outlet - 2 gang	AA1103FW	AA1103FB	AA1103DA	AA1103BS	AA1103BB	AA1103AB
For British Standard or Multistandard Socket Outlets with USB charger						
For single or double pole switched USB Type-A + Type-C - 1 gang	AA1113FW	AA1113FB	AA1113DA	AA1113BS	AA1113BB	AA1113AB
For single or double pole switched USB Type-A + Type-C - 2 gang	AA1115FW	AA1115FB	AA1115DA	AA1115BS	AA1115BB	AA1115AB
For switched USB Type-A + Type-C - 2 gang	AA1117FW	AA1117FB	AA1117DA	AA1117BS	AA1117BB	AA1117AB
For Cooker Unit						
For cooker unit - 2 gang	AC1109FW	AC1109FB	AC1109DA	AC1109BS	-	-
For 45A DP switch or Shaver Socket						
For 3 modules 45A Double Pole switch or Shaver socket - 2 gang	AC1136FW	AC1136FB	AC1136DA	AC1136BS	AC1136BB	AC1136AB

3. DIMENSIONS (mm)

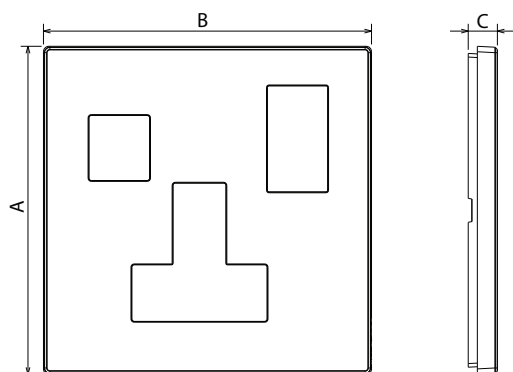

Cat. Nos	A	B	C
AA1100FW/FB/DA/BS/BB/AB AA1102FW/FB/DA/BS/BB/AB AA1113FW/FB/DA/BS/BB/AB	90	90	8
AA1101FW/FB/DA/BS/BB/AB AA1103FW/FB/DA/BS/BB/AB AC1109FW/FB/DA/BS AA1115FW/FB/DA/BS/BB/AB AA1117FW/FB/DA/BS/BB/AB AC1136FW/FB/DA/BS/BB/AB	90	157	8

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Underplate : PC

Finishes for FW/FB: PC

for BS/BB/AB: metal

for DA: metal + composite based

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° C to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane.

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach
10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.