


Arteor™ Advance Special plates for BS Socket outlets Statement Collection

Cat. No(s): AA1100SA/NB/SZ/SD/SB/SR/SC - AA1101SA/NB/SZ/SD/SB/SR/SC
AA1102SA/NB/SZ/SD/SB/SR/SC - AA1103SA/NB/SZ/SD/SB/SR/SC
AA1113SA/NB/SZ/SD/SB/SR/SC - AA1115SA/NB/SZ/SD/SB/SR/SC
AA1117SA/NB/SZ/SD/SB/SR/SC - AC1109SA/NB
AC1136SA/NB/SZ/SD/SB/SR/SC

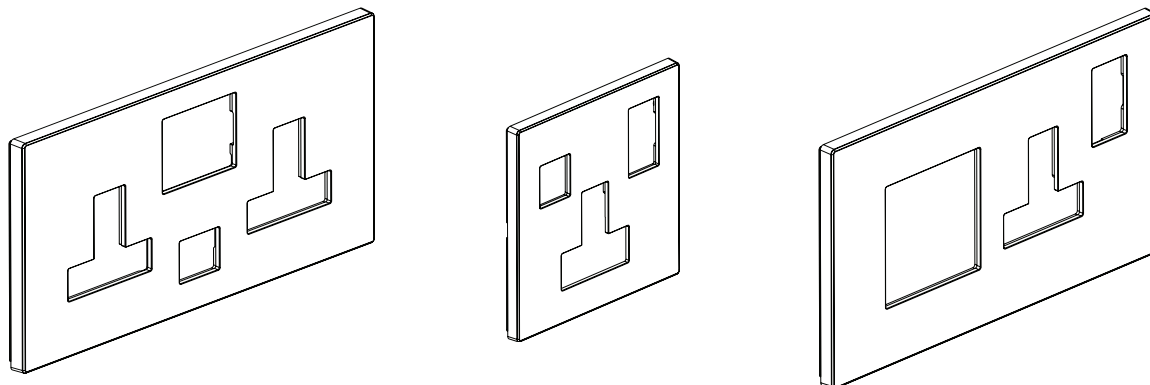


1. USE

Finishing plates.
The plates clip into notches on screw and/or claw fixings.
Protection film must be removed only once site work is fully completed.

2. RANGE

Designation	Finishes						
Statement Collection	Solid Aluminium	Midnight Blue	Solid Dark Bronze	Solid Sand	Solid Black	Solid Rose	Solid Champagne
For British Standard Socket Outlets							
For 5A/13A switched socket outlet - 1 gang	AA1100SA	AA1100NB	AA1100SZ	AA1100SD	AA1100SB	AA1100SR	AA1100SC
For 13A twin switched socket outlet - 2 gang	AA1101SA	AA1101NB	AA1101SZ	AA1101SD	AA1101SB	AA1101SR	AA1101SC
For 5A/13A unswitched socket outlet - 1 gang	AA1102SA	AA1102NB	AA1102SZ	AA1102SD	AA1102SB	AA1102SR	AA1102SC
For 5A/13A unswitched socket outlet 2 gang	AA1103SA	AA1103NB	AA1103SZ	AA1103SD	AA1103SB	AA1103SR	AA1103SC
For British Standard or Multistandard Socket Outlets with USB charger							
For single or double pole switched USB Type-A + Type-C - 1 gang	AA1113SA	AA1113NB	AA1113SZ	AA1113SD	AA1113SB	AA1113SR	AA1113SC
For single or double pole switched USB Type-A + Type-C - 2 gang	AA1115SA	AA1115NB	AA1115SZ	AA1115SD	AA1115SB	AA1115SR	AA1115SC
For switched USB Type-A + Type-C - 2 gang	AA1117SA	AA1117NB	AA1117SZ	AA1117SD	AA1117SB	AA1117SR	AA1117SC
For Cooker Unit							
For cooker unit - 2 gang	AC1109SA	AC1109NB	-	-	-	-	-
For 45A DP switch or Shaver Socket							
For 3 modules 45A Double Pole switch or Shaver socket - 2 gang	AC1136SA	AC1136NB	AC1136SZ	AC1136SD	AC1136SB	AC1136SR	AC1136SC

3. DIMENSIONS (mm)

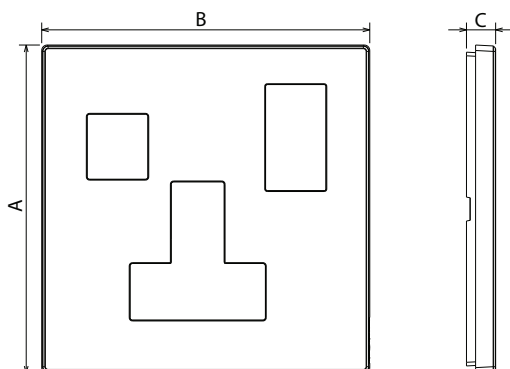

Cat. Nos	A	B	C
AA1100SA/NB/SZ/SD/SB/SR/SC AA1102SA/NB/SZ/SD/SB/SR/SC AA1113SA/NB/SZ/SD/SB/SR/SC	90	90	8
AA1101SA/NB/SZ/SD/SB/SR/SC AA1103SA/NB/SZ/SD/SB/SR/SC AA1117SA/NB/SZ/SD/SB/SR/SC AA1115SA/NB/SZ/SD/SB/SR/SC AC1109SA/NB AC1136SA/NB/SZ/SD/SB/SR/SC	90	157	8

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Adjuster : PC

Plate: Metal

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane.

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach
10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.