



Arteor™ Advance Plates Italian/US Standard Classic Collection


Cat. No(s): AC1101MW/MB/MT - AC1103MW/MB/MT
AC1107MW/MB/MT - AC1110MW/MB/MT
AC1111MW/MB/MT - AA1132MW/MB/MT

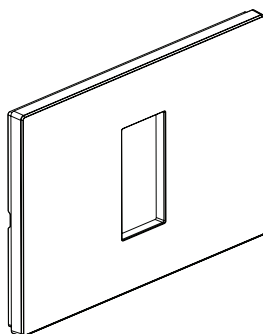

AC1101MW/MB/MT

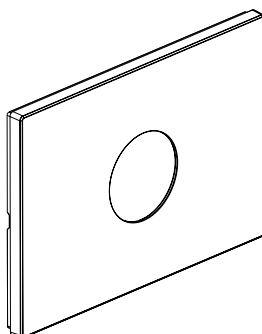

AA1132MW/MB/MT

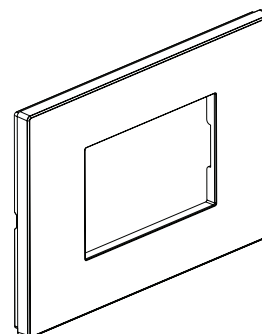

AC1107MW/MB/MT


1. USE

Finishing plates.
The plates clip into notches on screw and/or claw fixings.
Protection film must be removed only once site work is fully completed.

2. RANGE

Designation	Finishes		
Classic Collection	Matt White	Matt Black	Matt Titanium
Square Version			
1 module italian/US standard plate	AC1101MW	AC1101MB	AC1101MT
2 modules italian/US standard horizontal plate	AC1103MW	AC1103MB	AC1103MT
3 modules italian/US horizontal plate	AC1107MW	AC1107MB	AC1107MT
4 modules italian/french/german plate	AC1110MW	AC1110MB	AC1110MT
6 modules italian/french/german plate	AC1111MW	AC1111MB	AC1111MT
Slender Version			
2X4 italian/US horizontal plate for slender rotary dimmer	AA1132MW	AA1132MB	AA1132MT

3. DIMENSIONS (mm)

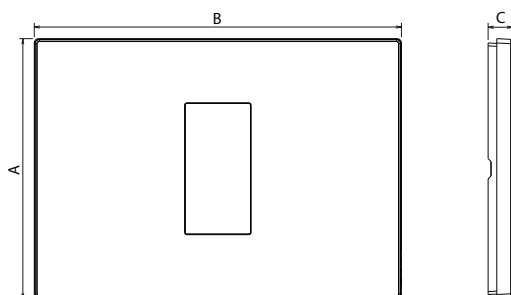

Cat. Nos	A	B	C
AA1132MW/MB/MT AC1101MW/MB/MT AC1103MW/MB/MT AC1107MW/MB/MT	90	127	8,5
AC1110MW/MB/MT	90	157	8,5
AC1111MW/MB/MT	90	237,5	8,5

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Adjuster : PC

Plate: PC

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach

10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.