



Arteor™ Advance Plates Italian/US Standard Decor Collection


Cat. No(s): AA1118FW/FB/DA/BS/BB/AB - AA1125FW/FB/DA/BS
AA1132FW/FB/DA/BS - AA1137FW/FB/DA/BS
AC1101FW/FB/DA/BS - AC1103FW/FB/DA/BS
AC1107FW/FB/DA/BS - AC1110FW/FB/DA/BS
AC1111FW/FB/DA/BS

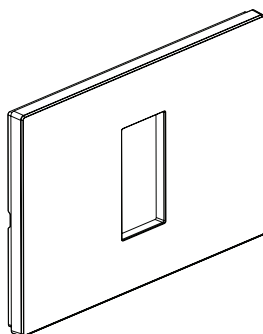

AC1101FW/FB/DA/BS

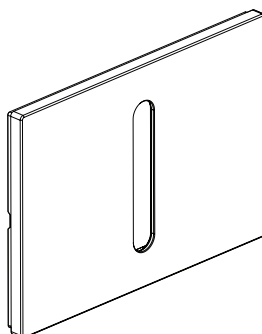

AA1137FW/FB/DA/BS

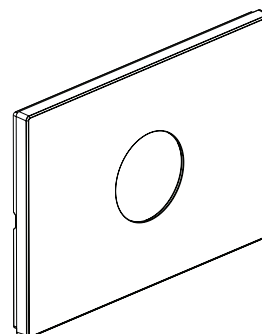

AA1132FW/FB/DA/BS

1. USE

Finishing plates.


The plates clip into notches on screw and/or claw fixings.

Protection film must be removed only once site work is fully completed.

2. RANGE

Designation	Finishes					
Decor Collection	Frosted White	Frosted Black	Dark Aluminium	Brushed Stainless Steel	Brushed Bronze	Brushed Antique Brass
Square Version						
1 module italian/US standard plate	AC1101FW	AC1101FB	AC1101DA	AC1101BS	-	-
2 modules italian/US standard horizontal plate	AC1103FW	AC1103FB	AC1103DA	AC1103BS	-	-
3 modules italian/US horizontal plate	AC1107FW	AC1107FB	AC1107DA	AC1107BS	-	-
4 modules italian/french/german plate	AC1110FW	AC1110FB	AC1110DA	AC1110BS	-	-
6 modules italian/french/german plate	AC1111FW	AC1111FB	AC1111DA	AC1111BS	-	-
Slender Version						
2 X4 Plate for 3 modules slender	AA1118FW	AA1118FB	AA1118DA	AA1118BS	AA1118BB	AA1118AB
2X4 italian/US horizontal plate for 1 module slender switch	AA1137FW	AA1137FB	AA1137DA	AA1137BS	-	-
2X4 italian/US horizontal plate for 2 modules slender switches	AA1125FW	AA1125FB	AA1125DA	AA1125BS	-	-
2X4 italian/US horizontal plate for slender rotary dimmer	AA1132FW	AA1132FB	AA1132DA	AA1132BS	-	-

3. DIMENSIONS (mm)

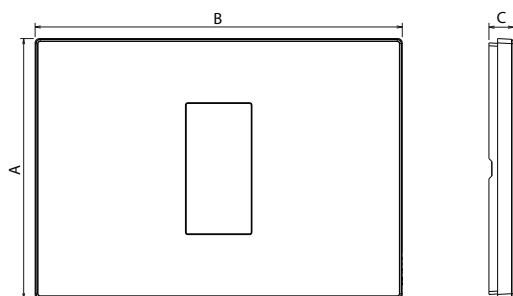

Cat. Nos	A	B	C
AA1118FW/FB/DA/BS/BB/AB AA1125FW/FB/DA/BS AA1132FW/FB/DA/BS AA1137FW/FB/DA/BS AC1101FW/FB/DA/BS AC1103FW/FB/DA/BS AC1107FW/FB/DA/BS	90	127	8.5
AC1110FW/FB/DA/BS	90	157	8.5
AC1111FW/FB/DA/BS	90	237.5	8.5

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Underplate : PC

Finishes for FW/FB: PC

for BS/BB/AB: metal

for DA: metal + composite based

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane.

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach
10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.