



Niloé™ STEP Socket outlets


Cat. No(s): 3 981 27B - 3 982 08 - 3 982 09 - 3 982 10 - 8 631 22 -
8 633 22 - 8 635 22 - 8 640 22 - 8 640 23 - 8 641 64 - 8 643 64 -
8 645 64 - 8 646 64

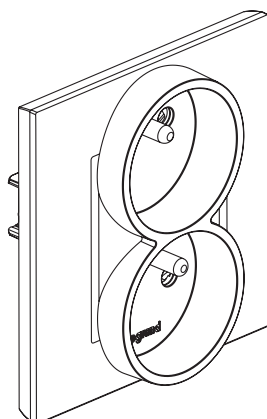

3 981 27B

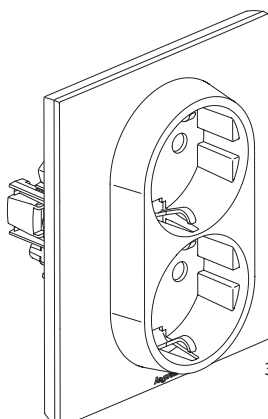

3 982 08/09/10, 8 63X 22,
8 64X 64

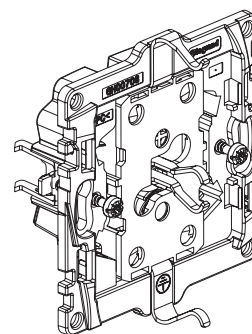

8 640 22/23


1. USE

Socket outlets with shutters.
Mechanisms supplied with protection cover.
To be equipped with plates one or several gangs.
Flush-mounting.
Screw or claw fixing.

2. RANGE

Description	White	Aluminium	Black	Sand	Mechanism Only
2x2 P+E german standard socket shutters automatic terminal	3 982 08, 8 631 22, 8 641 64	3 982 09, 8 633 22, 8 643 64	3 982 10, 8 635 22, 8 645 64	8 646 64	8 640 22
2x2P+E german socket shutters screw terminal	-	-	-	-	8 640 23
2x2P+E french socket shutters screw terminal	3 981 27B	-	-	-	-

3. DIMENSIONS (mm)

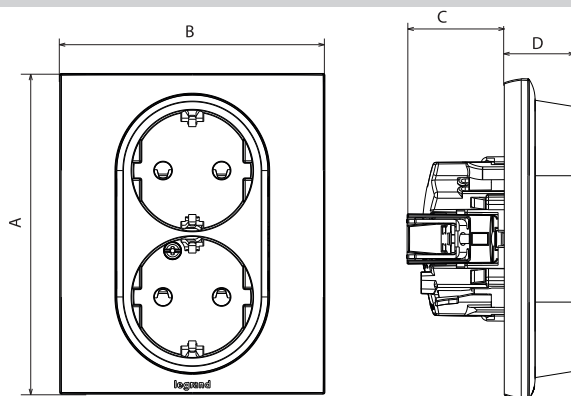

References	A	B	C	D
3 981 27B	89.5	86	41.7	19.2
3 982 08/09/10, 8 63X 22, 8 64X 64	104	86	31.6	22.3
8 640 22/23	82	71	28.9	22.5

4. CONNECTION

Terminal capacity: 2 x 2.5 mm²

Type of terminals:

automatic: 3 98X 08/09/10, 8 63X 22, 8 64X 64

screw: 3 981 27B, 8 640 23

Stripping length:

- 12 mm 3 98X 08/09/10, 8 63X 22, 8 64X 64

- 13 mm 3 981 27B, 8 640 23

Flexible or rigid cables compatible

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Protection against solid bodies and liquids: IP 20

Protection against impact: IK 04

■ 5.2 Material characteristics

Mat appearance

Mechanism housing: PC

Cover plate: PC

UV-resistant

Claws: steel

Support: PC

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place

650°C/30 s for other insulating components

■ 5.3 Electrical characteristics

Voltage: 250 V~

Current: 16 A

Frequency: 50/60 Hz

■ 5.4 Climate characteristics

Storage temperature: - 10° C to +70° C

Usage temperature: - 5° C to + 40° C

6. MAINTENANCE

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Maintenance with the following products:

Hexane, methylated spirit, soapy water, diluted ammonia, pure bleach diluted to 10%, window-cleaning products.

Caution: Always test before using other special cleaning products

7. STANDARDS AND APPROVALS

The undersigned, LEGRAND, declares that the radio-electric equipment type (Cat. Nos 3 981 27B - 3 982 08 - 3 982 09 - 3 982 10 - 8 631 22 -

8 633 22 - 8 635 22 - 8 640 22 - 8 640 23 - 8 641 64 - 8 643 64 - 8 645 64 - 8 646 64) complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website: www.legrand.com/ecatalogue