


Céliane™

Cat. No: CM0154

2 USB Type-C - 20 W - Power Delivery

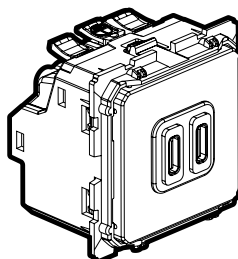

1. USE


Allows you to power and charge multimedia terminals: computers (PC, Mac), tablets and smartphones (Android, Apple) with or without Power Delivery technology.

Optimises the charging speed of terminals compatible with **USB Power Delivery and Quick Charge protocols**.

2. RANGE

2 USB Type-C + Type-C / 20 W - Power Delivery	Cat. Nos
To be equipped with support frame, cover plate and finishing plate - 2 modules - 40 mm deep minimum	CM0154

3. DIMENSIONS (mm)

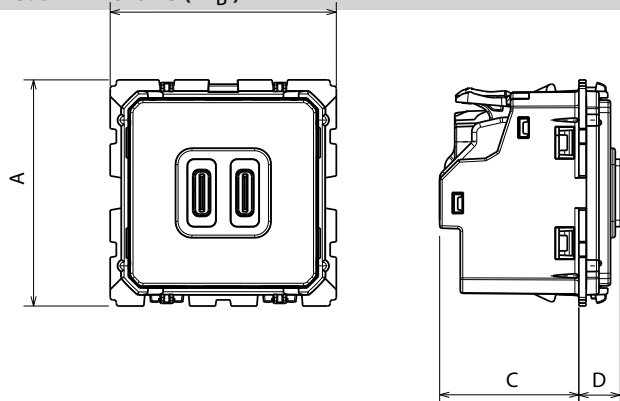

A	B	C	D
45	45	28	8

4. CONNECTION

Compatible with Rapido comb ref. CM0100

Terminal type: automatic

Terminal capacity: 2.5 mm²

Stripping length: 12 mm

Flexible or rigid cables compatible

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Protection against impact: IK 04

Protection against solid bodies and liquids: IP 40

■ 5.2 Material characteristics

PC

Halogen free

UV resistant

Self-extinguishing :

850° C / 30 s for insulating parts holding live parts in place

650° C / 30 s for other parts made of insulating materials

■ 5.3 Electrical characteristics

All values listed below are measured at an ambient temperature of + 20° and after 30 minutes of operation.

Nominal input voltage	100-240 V~
Nominal input frequency	50-60 Hz
Max. output power	20 W
Nominal input current	0.5 A
Max. nominal output current	3.0 A
Stand-by power consumption	0.05 W
Nominal output voltage	5 V~ *
Average efficiency in active mode	87 %
Consumption class without load and average level of efficiency	Level VI
Protection class	II - Low voltage

Optimise / voltage *

1 output	
5.0 V	3.0 A
9.0 V	2.2 A
12.0 V	1.6 A

2 output	
Type C ₁ : 5.0 V	1.5 A
Type C ₂ : 5.0 V	1.5 A

Note: To optimize the charging time of your device, ensure turn it off during the charging phase.

5. TECHNICAL CHARACTERISTICS *(continued)*

■ 5.4 Climatic characteristics

Storage temperature: - 20°C to + 70°C

Usage temperature: +5°C to + 35°C

6. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents:

Hexane, methylated spirits, soapy water, diluted ammonia, pure bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using other special cleaning products

7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

Refer to e-catalogue.