


Arteor™ Advance Blanking

Cat. No(s): AC150MW/MB/MT/CH/DB/RS - AC153MW/MB/MT/CH/DB/RS
 AC155MW/MB/MT - AC1501MW/MB/MT/CH/DB/RS
 AC1502MW/MB/MT

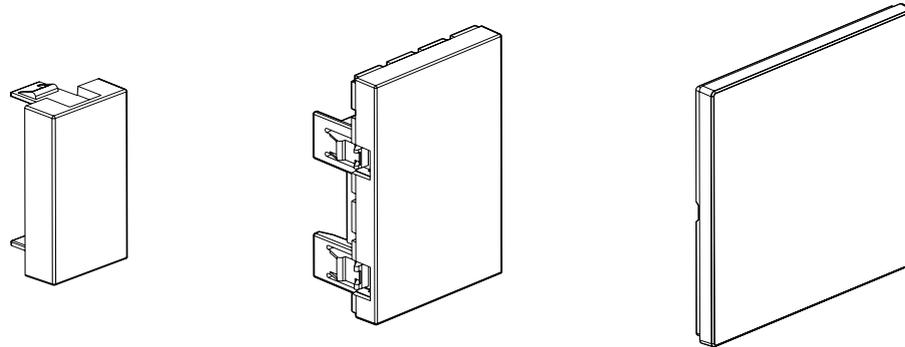


1. USE

Blanking module to be equipped with frame and plate.
 Blanking plate to be equipped with frame.

2. RANGE

Designation	Finishes					
	Classic Collection	Matt White	Matt Black	Matt Titanium	Champagne	Dark Bronze
Blank modules						
1 module	AC150MW	AC150MB	AC150MT	AC150CH	AC150DB	AC150RS
2 modules	AC153MW	AC153MB	AC153MT	AC153CH	AC153DB	AC153RS
3 modules	AC155MW	AC155MB	AC155MT	-	-	-
Blanking plates for British Standard						
For - 1 gang box	AC1501MW	AC1501MB	AC1501MT	AC1501CH	AC1501DB	AC1501RS
For - 2 gang box	AC1502MW	AC1502MB	AC1502MT	-	-	-

3. DIMENSIONS (mm)

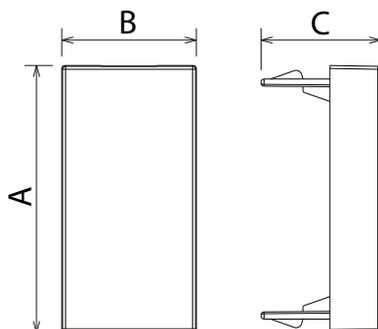

Cat. Nos	A	B	C
AC150MW/MB/MT/CH/DB/RS	45	22.5	20
AC153MW/MB/MT/CH/DB/RS	45	45	24.5
AC155MW/MB	67.5	45	24.5
AC1501MW/MB/MT/CH/DB/RS	90	90	8.5
AC1502MW/MB/MT	90	157	8.5

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Protection against impacts: IK 04

Protection against solid bodies and/or liquids: IP 20

■ 4.2 Material characteristics

Plate: PC

Halogen-free

UV-resistant

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane.

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach 10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.