



Surface-mounted power sockets French standard

Cat. No(s): 0 860 25L
0 861 25L

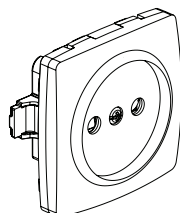

0 861 25L

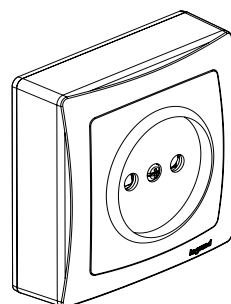

0 860 25L

1. USE


Power sockets 16 A conforming to french standard.
Devices supplied complete or modular mechanisms
2P sockets should only be used in the event of renovation.

2. RANGE

Description	Comple Unit	Modular component
2 P socket outlets with shutters	0 860 25L	0 861 25L


3. OVERALL DIMENSIONS (mm)

Comple unit

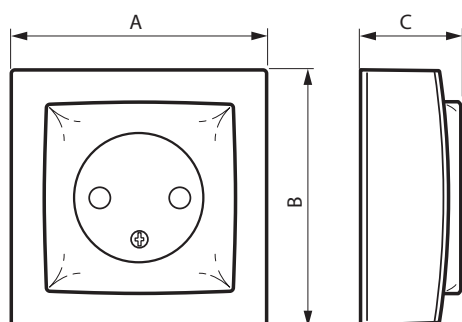

3. OVERALL DIMENSIONS (mm) (continued)

Modular component

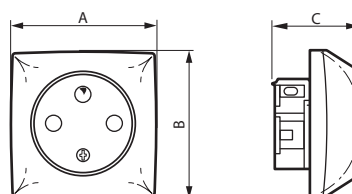

References	A	B	C
0 860 25L	72	72	36
0 861 25L	54	54	25.3

4. CONNEXION

Terminal type: automatic
Terminal capacity: from 1.5 mm² to 2.5 mm² (1 or 2 conductors)
Stripping length: 12 mm

5. TECHNICAL CHARACTERISTICS

■ 5.1 Protection index

Protection against solid bodies and liquids: IP 31D (complete product)
Protection against mechanical impact: IK 04

■ 5.2 Material characteristics

Frame, support: ABS

Cover plate: PC

UV resistant

Halogen-free

Self-extinguishing:

+ 850° C / 30 s for insulating components holding in place live parts.

+ 650° C / 30 s for the other insulating components.

■ 5.3 Electric characteristics

Voltage: 250 Vac

Current: 16 A

Fréquency: 50 Hz

■ 5.4 Climatic characteristics

Operating temperature: -10° to +40°C

Storage temperature: -25°C to +60°C

6. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane, Methylated spirits, Soapy water, Diluted ammonia, Diluted pure bleached 10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.

7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e.catalogue