


Arteor™ Advance IP44 Weatherproof plate

Cat. No(s): AC1124MW

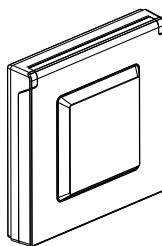

AC1124MW


1. USE

Weatherproof plate for covering 1 and 2 module mechanism.
Supplied with frame.

2. RANGE

Description	Type	Matt White	Matt Black	Matt Titanium
FR/B-SCH-BS WEATHERP. PLATE	1-gang	AC1124MW		

3. DIMENSIONS (mm)

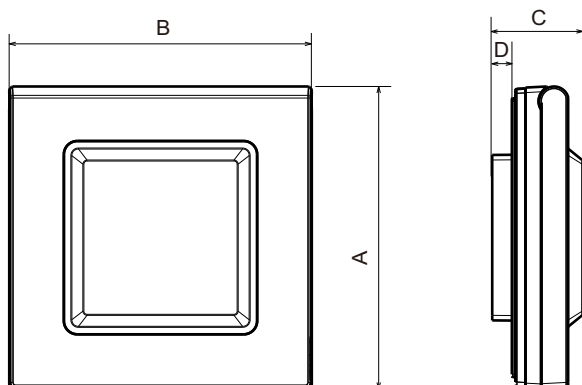

References	A	B	C	D
AC1124MW	90	90	26.9	6.9

4. TECHNICAL CHARACTERISTICS

■4.1 Mechanical characteristics

Impact test: IK04
Protection against solids & liquids: IP44

■4.2 Material characteristics

Plate: PC+TPU
Frame: PC+TPU
Self-extinguishing:
+ 850° C / 30 s for insulating parts holding live parts in place
+ 650° C / 30 s for other parts made of insulating materials

■4.3 Climatic characteristics

Usage temperature: -5°C to +35°C
Storage temperature: -10°C to +70°C

5. CARE

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products: Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using special cleaning products.

6. CONFORMITY - APPROVALS

Conform to IEC 60670-1 standard