



Arteor™ Advance Plates Italian/US Standard Statement Collection


Cat. No(s): AA1118NB/SA/SB/SC/SD/SR/SZ - AA1125NB/SA
AA1132NB/SA - AA1137NB/SA - AC1101NB/SA
AC1103NB/SA - AC1107NB/SA - AC1110NB/SA
AC1111NB/SA

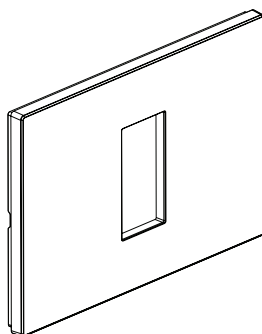

AC1101NB/SA

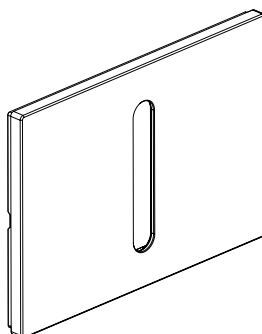

AA1137NB/SA

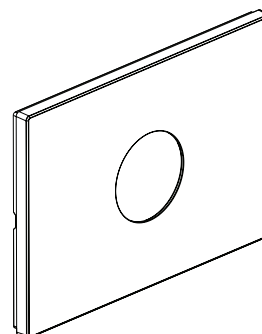

AA1132NB/SA

1. USE

Finishing plates.


The plates clip into notches on screw and/or claw fixings.

Protection film must be removed only once site work is fully completed.

2. RANGE

Designation	Finishes						
Statement Collection	Midnight Blue	Solid Aluminium	Solid Black	Solid Champagne	Solid Sand	Solid Rose	Solid Dark Bronze
Square Version							
1 module italian/US standard plate	AC1101NB	AC1101SA	-	-	-	-	-
2 modules italian/US standard horizontal plate	AC1103NB	AC1103SA	-	-	-	-	-
3 modules italian/US horizontal plate	AC1107NB	AC1107SA	-	-	-	-	-
4 modules italian/french/german plate	AC1110NB	AC1110SA	-	-	-	-	-
6 modules italian/french/german plate	AC1111NB	AC1111SA	-	-	-	-	-
Slender Version							
2 X4 Plate for 3 modules slender	AA1118NB	AA1118SA	AA1118SB	AA1118SC	AA1118SD	AA1118SR	AA1118SZ
2X4 italian/US horizontal plate for 1 module slender switch	AA1137NB	AA1137SA	-	-	-	-	-
2X4 italian/US horizontal plate for 2 modules slender switches	AA1125NB	AA1125SA	-	-	-	-	-
2X4 italian/US horizontal plate for slender rotary dimmer	AA1132NB	AA1132SA	-	-	-	-	-

3. DIMENSIONS (mm)

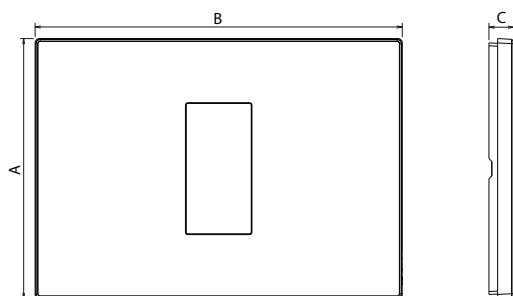

Cat. Nos	A	B	C
AA1118NB/SA/SB/SC/SD/SR/SZ AA1125NB/SA AA1132NB/SA AA1137NB/SA AC1101NB/SA AC1103NB/SA AC1107NB/SA	90	127	8.5
AC1110NB/SA	90	157	8.5
AC1111NB/SA	90	237.5	8.5

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Ajuster: PC

Plate: Metal

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane.

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach
10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.