


Connected outdoor luminosity and temperature sensor

Cat. No(s) : 069061

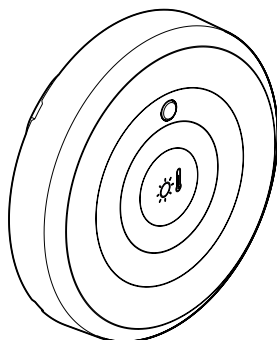


1. USE

Measures outdoor brightness and temperature. Enables automated scenarios.
Sends alerts or notifications to the Home + Control application based on defined thresholds.

2. GAMME

Used to complement your smart home system, requires the prior installation of a Zigbee 3.0-compatible gateway.
Supplied with batteries (x2).

3. DIMENSIONS (mm)

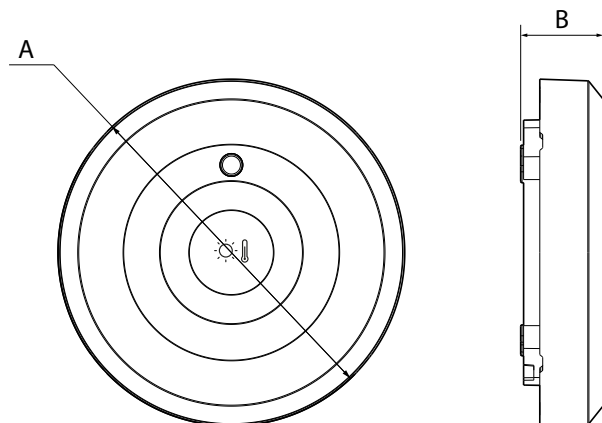

A	B
119	28

4. CONNECTION

Measurement thresholds

Temperature range: -20°C to +65°C
Brightness range: 0 to 83 000 lux
Humidity range: 0 to 100%
Wireless range: 180 m

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Impact protection: IK04
Protection against solid objects and liquids: IP45

■ 5.2 Material characteristics

ABS and PC
UV resistant

■ 5.3 Electrical characteristics

Batteries (x2) : 1,5 V - AAA

■ 5.4 Climatic characteristics

Storage temperature: -20°C to +70°C
Operating temperature: -20°C to +65°C

6. CARE

Surface cleaning with a cloth.
Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents:

Hexane, methylated spirits, soapy water, diluted ammonia, pure bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using other special cleaning products



Take care to recycle the battery appropriately.

7. STANDARDS AND APPROVALS

Complies with international standards relating to electrical safety and the use of radio frequencies.

The undersigned, LEGRAND, declares that the radio-electric equipment type (0 690 61) complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website: www.legrand.com/ecatalogue