



2P+E rotating multi-outlet plugs 2 side outputs with USB C-Type

Cat. No(s): 0 496 18/19 - 6 944 32/33

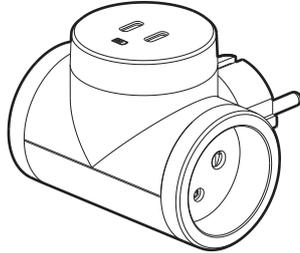

0 496 18/19

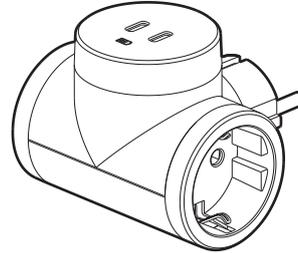

6 944 32/33


1. USE

Socket block which pivots on its axis for connection to 2P+E wall outlets.
 2 side outputs + USB Type-C+C with Power Delivery charger for fast charging mobile devices such as smartphones or tablets.

2. RANGE

Description	French-Belgian standard		German standard	
	White/Dark Grey	Aluminium/ Dark Grey	White/Dark Grey	Aluminium/ Dark Grey
2P+E multi-outlet plugs with safety shutter 2 x 2P+E side outputs + 1 USB Type-C+C charging module	0 496 18	0 496 19	6 944 32	6 944 33

3. DIMENSIONS (mm)

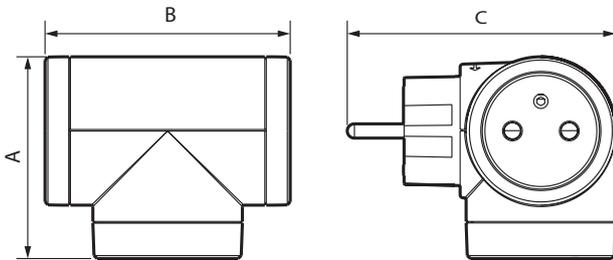

Cat. Nos	A	B	C
0 496 18/19	68	82	90
6 944 32/33	68	88	90

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact tests: IK 04
 Protection against solid/bodies and liquids: IP 20

■ 4.2 Material characteristics

Plastic + thermoplastic Matt White RAL 9003/Dark Grey RAL 7024
 Painted Aluminium
 Halogen-free
 UV-resistant
 Self-extinguishing:
 750°C/30 s for insulating components holding live parts in place.
 650°C/30 s for other insulating components.

■ 4.3 Electrical characteristics

Voltage: 230 V~
 Frequency: 50 Hz
 Current: 16 A
 Power: max. 3680 W

USB socket:

2 USB Type-C port.
 Power delivered:
 1 x USB C : 5V= 3A 15W; 9V= 2.22A 20W, 12V= 1.67A 20W
 2 x USB C : 5V= 3A 15W max
 Average active efficiency:
 _ 5V= : 84%
 _ 9V= : 87%
 _ 12V= : 87%
 Efficiency at low load (10%):
 _ 5V= : 81%
 _ 9V= : 76%
 _ 12V= : 77%

No-load power consumption: 0.06 W

■ 4.4 Climate characteristics

Usage temperature: -5°C to +35°C
 Storage temperature: -20°C to +70°C

5. CARE

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards

See e. catalogue.