



Multi-outlet extensions French-Belgian standard

Cat. No(s): 0 496 20/21/22/23/24/25/26/27/28/30/32/33/34/35
 0 496 36/37/38/39/40/41/42/43/52/54/56/57/58/59

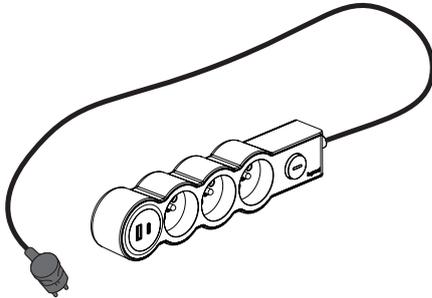

0 496 52/54

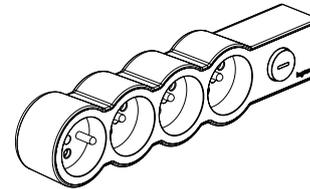

0 496 40/41


1. USE

Multi-outlet extensions: 3, 4, and 5 x 2P+E flush sockets with shutter, with 2P+E plug, with or without a cord.
 Socket units with recesses at a 45° angle (except for 1 at 90° for connecting a transformer).
 With USB Type-A+C charger.

2. RANGE

FRENCH-BELGIAN STANDARD	Cable length 1.5 m 3 G 1 mm ²		Cable length 1.5 m 3 G 1.5 mm ²		Cable length 3 m 3 G 1.5 mm ²		to be wired	
	White/ Light grey	Black/ Dark grey	White/ Light grey	Black/ Dark grey	White/ Light grey	Black/ Dark grey	White/ Light grey	Black/ Dark grey
3 x 2 P+T + switch	0 496 20	0 496 22	0 496 21	0 496 23	0 496 32	0 496 33	0 496 38	0 496 39
4 x 2 P+T + switch	0 496 24	0 496 26	0 496 25	0 496 27	0 496 34	0 496 35	0 496 40	0 496 41
5 x 2 P+T + switch	0 496 28	0 496 30	-	-	0 496 36	0 496 37	0 496 42	0 496 43
3 x 2 P+T switch+ 2 USB Type-A+C	0 496 52	0 496 54	-	-	-	-	-	-
4 x 2 P+T switch+ 2 USB Type-A+C	0 496 56	0 496 58	0 496 57	0 496 59	-	-	-	-

3. DIMENSIONS (mm)

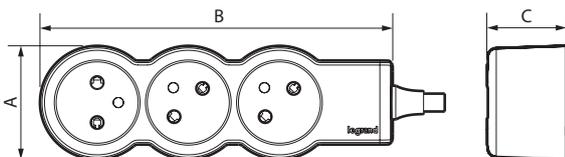

Cat. No(s)	A	B	C
3 x 2P+E	54	166.5	37.5
4 x 2P+E	54	209.5	37.5
5 x 2P+E	54	252.5	37.5

4. CONNECTION

For catalogue numbers to be wired: 0 496 38/39/40/41/42/43

Terminal type: with screws
 Terminal capacity: 3 x 1.5 mm²
 Stripping length: 8 mm

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Impact tests: IK 04
 Protection against solid bodies and liquids: IP 20

■ 5.2 Material characteristics

Plastic
 Matt white RAL 9003 / Matt light grey RAL 7047
 Black RAL 9017 / Dark grey RAL 7024
 Halogen-free
 UV-resistant

Self-extinguishing:

750°C/30 s for insulating components holding live parts in place.
 650°C/30 s for other insulating components.

■ 5.3 Electrical characteristics

Voltage: 230 V~
 Frequency: 50 Hz
 Current: 16 A
 Power: max. 3680 W

USB socket:

1 USB Type-A port + 1 USB Type-C port
 5.0 V= - 3.0 A - 15 W max.
 Average active efficiency: 84.3%
 Low-load efficiency (10%): 82.4%
 Electricity consumption when not charging: 0.09 W

■ 5.4 Climate characteristics

Usage temperature: -5°C to +35°C
 Storage temperature: -20°C to +70°C

6. CARE

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene..

Caution: Always test before using other special cleaning products.

7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards

See e. catalogue.