



Arteor™ Advance Plates German/French standard Classic Collection

Cat. No(s): AC1120MW/MB/MT - AC1121MW/MB/MT - AC1122MW/MB/MT
AC1123MW/MB/MT - AC1133MW/MB/MT

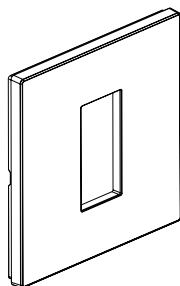

AC1120MW/MB/MT

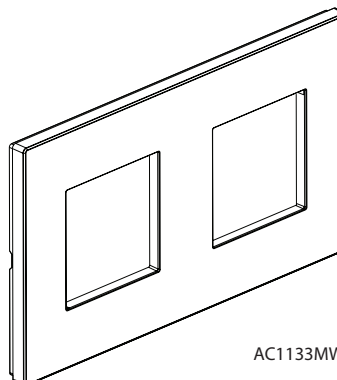

AC1133MW/MB/MT


1. USE

Finishing plates.
The plates clip into notches on screw and/or claw fixings.
Protection film must be removed only once site work is fully completed.

2. RANGE

Designation	Finishes		
Classic Collection	Matt White	Matt Black	Matt Titanium
Square Version			
1 module german/french standard plate	AC1120MW	AC1120MB	AC1120MT
2 modules german/french standard plate	AC1121MW	AC1121MB	AC1121MT
2x6 modules german/french standard plate	AC1122MW	AC1122MB	AC1122MT
3x2 modules german/french standard horizontal plate	AC1123MW	AC1123MB	AC1123MT
2x2 modules german/french standard horizontal plate	AC1133MW	AC1133MB	AC1133MT

3. DIMENSIONS (mm)

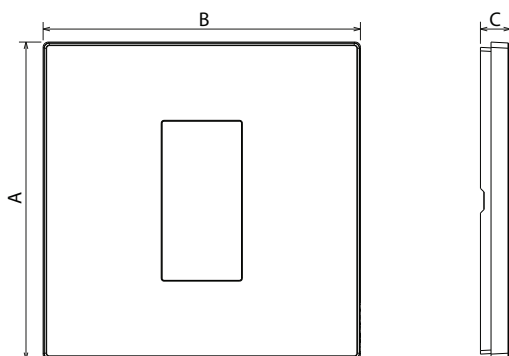

Cat. Nos	A	B	C
AC1120MW/MB/MT AC1121MW/MB/MT	90	90	8.5
AC1133MW/MB/MT	90	157	8.5
AC1123MW/MB/MT	90	237.5	8.5
AC1122MW/MB/MT	178	237.5	8.5

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Adjuster : PC

Plate: PC

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexan.

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach
10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.