



Arteor™ Advance
Plates German/French standard
Decor Collection

Cat. No(s): AC1120FW/FB/DA/BS - AC1121FW/FB/DA/BS - AC1122FW/FB/DA/BS
AC1123FW/FB/DA/BS - AC1133FW/FB/DA/BS

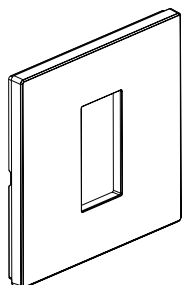

AC1120FW/FB/DA/BS

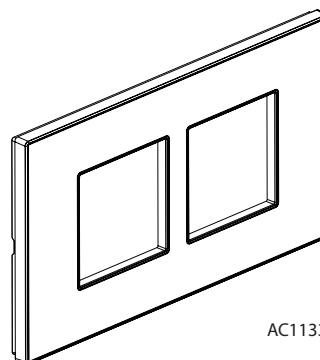

AC1133FW/FB/DA/BS


1. USE

Finishing plates.
The plates clip into notches on screw and/or claw fixings.
Protection film must be removed only once site work is fully completed.

2. RANGE

Designation Decor Collection	Finishes			
	Frosted White	Frosted Black	Dark Aluminium	Brushed Stainless Steel
Square Version				
1 module german/french standard plate	AC1120FW	AC1120FB	AC1120DA	AC1120BS
2 modules german/french standard plate	AC1121FW	AC1121FB	AC1121DA	AC1121BS
2x6 modules german/french standard plate	AC1122FW	AC1122FB	AC1122DA	AC1122BS
3x2 modules german/french standard horizontal plate	AC1123FW	AC1123FB	AC1123DA	AC1123BS
2x2 modules german/french standard horizontal plate	AC1133FW	AC1133FB	AC1133DA	AC1133BS

3. DIMENSIONS (mm)

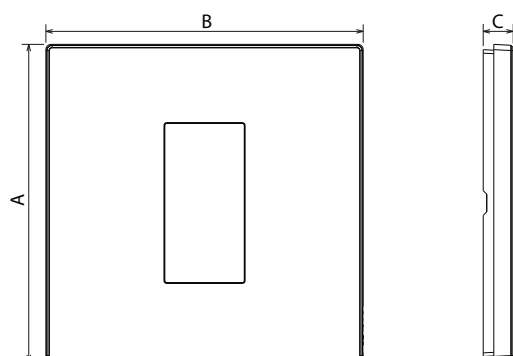

Cat. Nos	A	B	C
AC1120FW/FB/DA/BS AC1121FW/FB/DA/BS	90	90	8.5
AC1133FW/FB/DA/BS	90	157	8.5
AC1123FW/FB/DA/BS	90	237.5	8.5
AC1122FW/FB/DA/BS	178	237.5	8.5

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Underplate : PC

Finishies for FW/FB: PC

for BS: metal

for DA: metal + composite based

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane.

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach
10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.