


Arteor™ Advance with Netatmo Plate British Standard Statement Collection

Cat. No(s): AC1112NB/SA/SB/SC/SD/SR/SZ

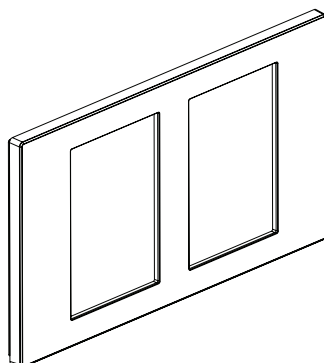

1. USE

Finishing plates.


The plates clip into notches on screw and/or claw fixings.

Protection film must be removed only once site work is fully completed.

2. RANGE

Designation	Finishes						
Statement Collection	Solid Aluminium	Midnight Blue	Solid Dark Bronze	Solid Sand	Solid Black	Solid Rose	Solid Champagne
Square Version							
2 x 3 modules british standard plate for IOT socket- 2 gang	AC1112SA	AC1112NB	AC1112SZ	AC1112SD	AC1112SB	AC1112SR	AC1112SC

3. DIMENSIONS (mm)

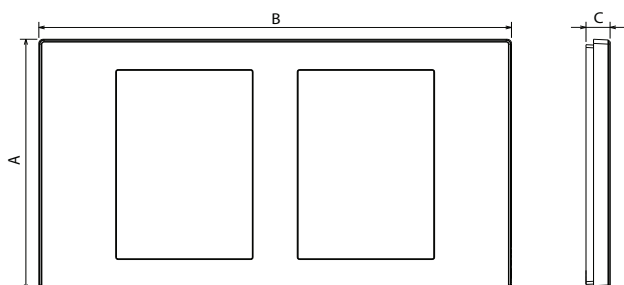

Cat. Nos	A	B	C
AC1112NB/SA/SB/SC/SD/SR/SZ	90	127	8

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Protection against impacts: IK 04

Protection against solid bodies and/or liquids: IP 20

■ 4.2 Material characteristics

Adjuster : PC

Plate: Metal

Self-extinguishing: 650°C/30 s

Halogen-free

UV-resistant

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane.

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach 10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.