



Arteor™ Advance
Plate US & South African standard
Classic Collection


Cat. No(s): AC1118MW/MB/MT - AC1125MW/MB/MT
AC1127MW/MB/MT - AC1128MW/MB/MT
AC1129MW/MB/MT - AC1130MW/MB/MT
AC1131MW/MB/MT - AC1135MW/MB/MT

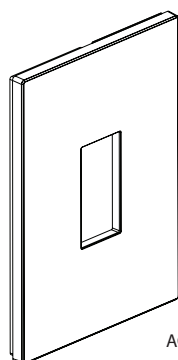

AC1131MW/MB/MT

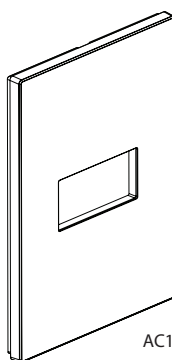

AC1135MW/MB/MT

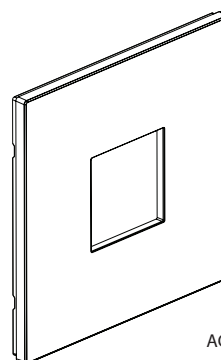

AC1118MW/MB/MT


1. USE

Finishing plates.
The plates clip into notches on screw and/or claw fixings.
Protection film must be removed only once site work is fully completed.

2. RANGE

Designation	Finishes		
Classic Collection	Matt White	Matt Black	Matt Titanium
Square Version			
2 modules US & south african plate 4"x4"	AC1118MW	AC1118MB	AC1118MT
2 vertical modules US & south african plate 2"x4"	AC1125MW	AC1125MB	AC1125MT
3 horizontal modules US & south african plate 2"x4"	AC1127MW	AC1127MB	AC1127MT
3 vertical modules US & south african plate 4"x4"	AC1128MW	AC1128MB	AC1128MT
4 vertical modules US & south african plate 4"x4"	AC1129MW	AC1129MB	AC1129MT
2x3 modules US & south african plate 4"x4"	AC1130MW	AC1130MB	AC1130MT
1 vertical module US & south african plate 2"x4"	AC1131MW	AC1131MB	AC1131MT
1 horizontal module US & south african plate 2"x4"	AC1135MW	AC1135MB	AC1135MT

3. DIMENSIONS (mm)

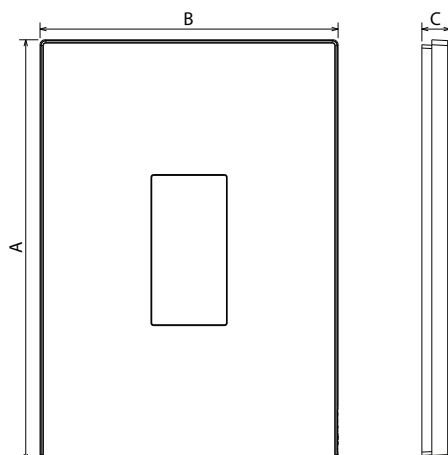

Cat. Nos	A	B	C
AC1125MW/MB/MT AC1127MW/MB/MT AC1131MW/MB/MT AC1135MW/MB/MT	127	90	8,5
AC1118MW/MB/MT AC1128MW/MB/MT AC1129MW/MB/MT AC1130MW/MB/MT	127	127	8,5

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Adjuster : PC

Plate: PC

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach

10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.