



Arteor™ Advance Plate US & South African standard Decor Collection


Cat. No(s): AA1138FW/FB/DA/BS - AA1139FW/FB/DA/BS - AA1140FW/FB/DA/BS
AA1141FW/FB/DA/BS - AA1144FW/FB/DA/BS - AA1145FW/FB/DA/BS
AB1142FW/FB/DA/BS - AB1143FW/FB/DA/BS - AC1118FW/FB/DA/BS
AC1125FW/FB/DA/BS - AC1127FW/FB/DA/BS - AC1128FW/FB/DA/BS
AC1129FW/FB/DA/BS - AC1130FW/FB/DA/BS
AC1131FW/FB/DA/BS - AC1135FW/FB/DA/BS

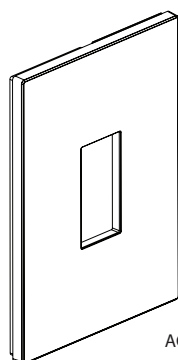

AC1131FW/FB/DA/BS

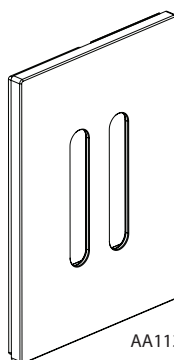

AA1138FW/FB/DA/BS

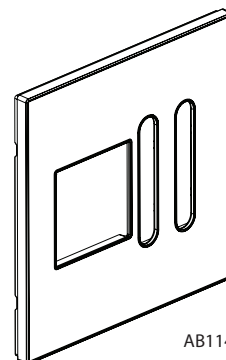

AB1143FW/FB/DA/BS


1. USE

Finishing plates.
The plates clip into notches on screw and/or claw fixings.
Protection film must be removed only once site work is fully completed.

2. RANGE

Designation	Finishes			
Decor Collection	Frosted White	Frosted Black	Dark Aluminium	Brushed Stainless Steel
Square Version				
2 modules US & south african plate 4"x 4"	AC1118FW	AC1118FB	AC1118DA	AC1118BS
2 vertical modules US & south african plate 2"x 4"	AC1125FW	AC1125FB	AC1125DA	AC1125BS
3 horizontal modules US & south african plate 2"x 4"	AC1127FW	AC1127FB	AC1127DA	AC1127BS
3 vertical modules US & south african plate 4"x 4"	AC1128FW	AC1128FB	AC1128DA	AC1128BS
4 vertical modules US & south african plate 4"x 4"	AC1129FW	AC1129FB	AC1129DA	AC1129BS
2x3 modules US & south african plate 4"x 4"	AC1130FW	AC1130FB	AC1130DA	AC1130BS
1 vertical module US & south african plate 2"x 4"	AC1131FW	AC1131FB	AC1131DA	AC1131BS
1 horizontal module US & south african plate 2"x 4"	AC1135FW	AC1135FB	AC1135DA	AC1135BS
Slender version				
2 vertical modules US & south african plate 2"x 4"	AA1138FW	AA1138FB	AA1138DA	AA1138BS
2 modules US & south african plate 4"x 4"	AA1139FW	AA1139FB	AA1139DA	AA1139BS
1 module US & south african plate 4"x 4"	AA1140FW	AA1140FB	AA1140DA	AA1140BS
3 modules US & south african plate 4"x 4"	AA1141FW	AA1141FB	AA1141DA	AA1141BS
4 modules US & south african plate 4"x 4"	AA1144FW	AA1144FB	AA1144DA	AA1144BS
1 vertical module US & south african plate 2"x 4"	AA1145FW	AA1145FB	AA1145DA	AA1145BS
Hybrid version				
2 modules Square + 1 module Slender switch US & south african plate 4"x 4"	AB1142FW	AB1142FB	AB1142DA	AB1142BS
2 modules Square + 2 modules Slender switch US & south african plate 4"x 4"	AB1143FW	AB1143FB	AB1143DA	AB1143BS

3. DIMENSIONS (mm)

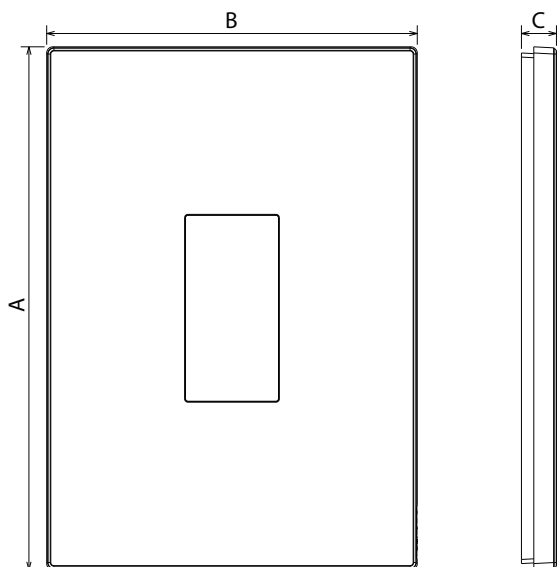

Cat. Nos	A	B	C
AA1138FW/FB/DA/BS AA1145FW/FB/DA/BS AC1125FW/FB/DA/BS AC1127FW/FB/DA/BS AC1131FW/FB/DA/BS AC1135FW/FB/DA/BS	127	90	8,5
AA1139FW/FB/DA/BS AA1140FW/FB/DA/BS AA1141FW/FB/DA/BS AA1144FW/FB/DA/BS AB1142FW/FB/DA/BS AB1143FW/FB/DA/BS AC1118FW/FB/DA/BS AC1128FW/FB/DA/BS AC1129FW/FB/DA/BS AC1130FW/FB/DA/BS	127	127	8,5

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Adjuster : PC

Finishes for FW/FB: PC

for BS: metal

for DA: metal + composite based

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach

10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.