



Arteor™ Advance Plate US & South African standard Statement Collection


Cat. No(s): AA1138NB/SA - AA1139NB/SA - AA1140NB/SA - AA1141NB/SA
AA1144NB/SA - AA1145NB/SA - AB1142NB/SA - AB1143NB/SA
AC1118NB/SA - AC1125NB/SA - AC1127NB/SA - AC1128NB/SA
AC1129NB/SA - AC1130NB/SA - AC1131NB/SA - AC1135NB/SA

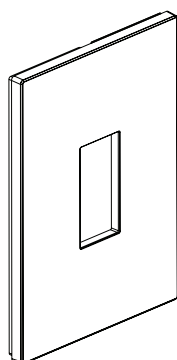

AC1131NB/SA

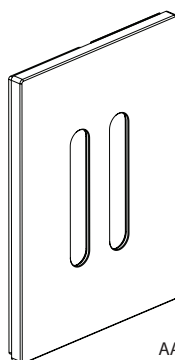

AA1138NB/SA

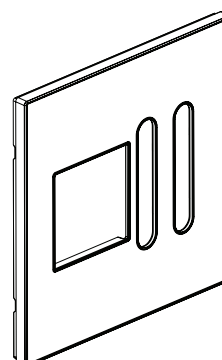

AB1143NB/SA


1. USE

Finishing plates.
The plates clip into notches on screw and/or claw fixings.
Protection film must be removed only once site work is fully completed.

2. RANGE

Designation <i>Statement Collection</i>	Finishes	
	Midnight Blue	Solid Aluminium
Square Version		
2 modules US & south african plate 4"x4"	AC1118NB	AC1118SA
2 vertical modules US & south african plate 2"x4"	AC1125NB	AC1125SA
3 horizontal modules US & south african plate 2"x4"	AC1127NB	AC1127SA
3 vertical modules US & south african plate 4"x4"	AC1128NB	AC1128SA
4 vertical modules US & south african plate 4"x4"	AC1129NB	AC1129SA
2x3 modules US & south african plate 4"x4"	AC1130NB	AC1130SA
1 vertical module US & south african plate 2"x4"	AC1131NB	AC1131SA
1 horizontal module US & south african plate 2"x4"	AC1135NB	AC1135SA
Slender version		
2 vertical modules US & south african plate 2"x 4"	AA1138NB	AA1138SA
2 modules US & south african plate 4"x 4"	AA1139NB	AA1139SA
1 module US & south african plate 4"x 4"	AA1140NB	AA1140SA
3 modules US & south african plate 4"x 4"	AA1141NB	AA1141SA
4 modules US & south african plate 4"x 4"	AA1144NB	AA1144SA
1 vertical module US & south african plate 2"x 4"	AA1145NB	AA1145SA
Hybrid version		
2 modules Square + 1 module Slender switch US & south african plate 4"x 4"	AB1142NB	AB1142SA
2 modules Square + 2 modules Slender switch US & south african plate 4"x 4"	AB1143NB	AB1143SA

3. DIMENSIONS (mm)

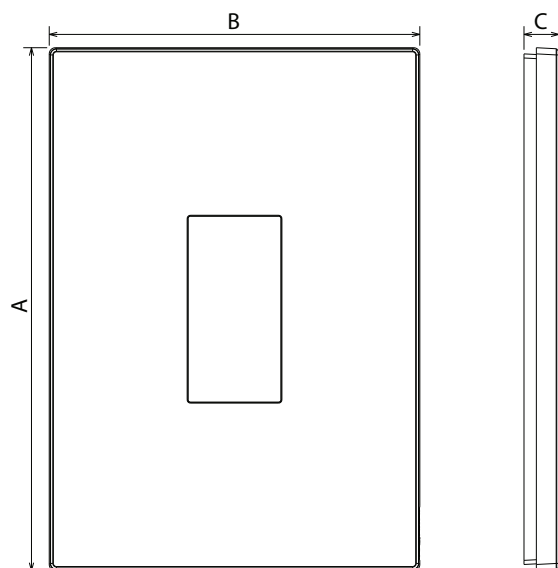

Cat. Nos	A	B	C
AA1138NB/SA AA1145NB/SA AC1125NB/SA AC1127NB/SA AC1131NB/SA AC1135NB/SA	127	90	8,5
AA1139NB/SA AA1140NB/SA AA1141NB/SA AA1144NB/SA AB1142NB/SA AB1143NB/SA AC1118NB/SA AC1128NB/SA AC1129NB/SA AC1130NB/SA	127	127	8,5

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 02

■ 4.2 Material characteristics

Adjuster : PC

Plate: Metal

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10° c to + 70° C

Usage temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane

Methylated spirits, Soapy water, diluted ammonia, diluted pure bleach
10%, Glass cleaning substance, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.