



Arteor™ Advance Adapter for data socket

Cat. No(s): AC173CH/DB/MB/MT/MW/RS
AC174CH/DB/MB/MT/MW/RS

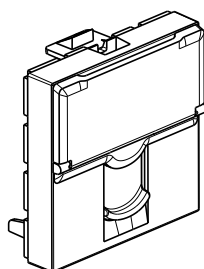

AC173CH/DB/MB/MT/MW/RS

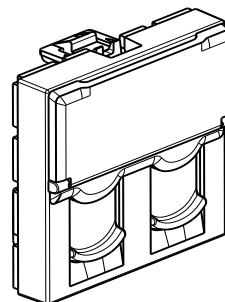

AC174CH/DB/MB/MT/MW/RS


1. USE

Single and double-port data socket faceplates, equipped with transparent identification label holder.

2. RANGE

Designation	Champagne	Dark Bronze	Matt Black	Matt Titanium	Matt White	Rose
Single Systimax adapter 1 module	AC173CH	AC173DB	AC173MB	AC173MT	AC173MW	AC173RS
Duplex Systimax adapter - 2 modules	AC174CH	AC174DB	AC174MB	AC174MT	AC174MW	AC174RS

3. DIMENSIONS (mm)

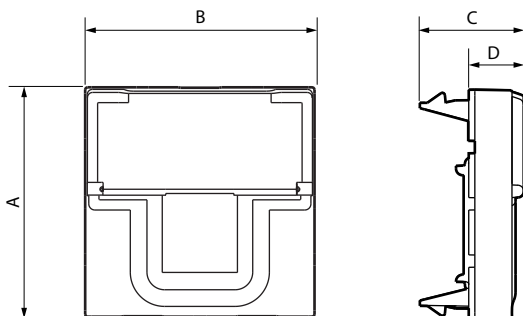

A	B	C	D
45	45	20.5	11

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact resistance : IK 03

Penetration against solid bodies and liquids : IP 20

■ 4.2 Material characteristics

Faceplate: PC

Identification label holder made of transparent PC

Halogen-free

UV-resistant

Self-extinguishing: 650°C/30 s

4. TECHNICAL CHARACTERISTICS (continued)

■ 4.3 Climate characteristics

Storage temperature : -10°C to +70°C

Usage temperature : -5°C to +35°C

5. CLEANING

Surface cleaning with a cloth.

Do not use acetone, tar remover, trichloroethylene.

Resistant to the following products: Methylated spirit, soapy water, diluted ammonia, bleach diluted to 10 %, windowcleaning products, pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e. catalogue.