


Arteor™ Advance Preterminated 2 female RCA sockets

Cat. No(s): AC4440MB/MT/MW

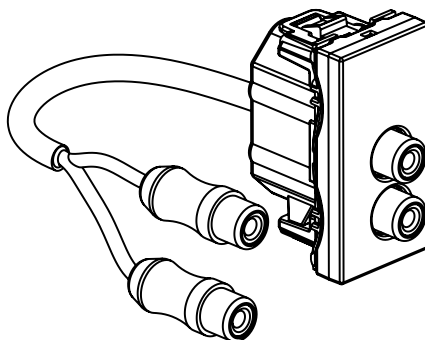


1. USE

Provide the stereo audio link for any peripheral device such as a DVD drive, camera, video recorder.
Equipped with 15cm cord.
Min box depth : 50mm
To be equipped with frame and plate.

2. RANGE

Designation	Finishes		
	Matt White	Matt Black	Matt Titanium
1 module 2 female RCA socket	AC4440MW	AC4440MB	AC4440MT

3. DIMENSIONS (mm)

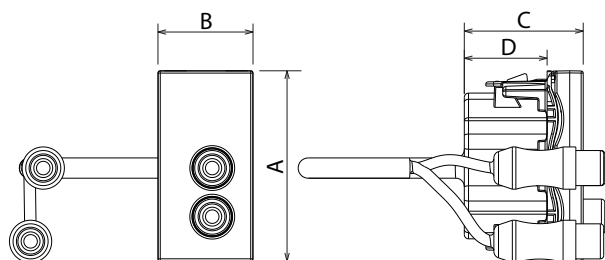


Cat. Nos	A	B	C	D
AC4440MW/MB/MT	45.05	22.5	28.15	19.6

4. TECHNICAL CHARACTERISTICS

■ 4.1 Electrical characteristics

Transmission quality depends directly on the quality of the cable and the connection to the sockets.

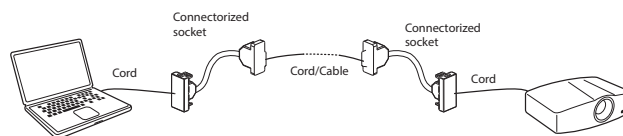

RCA preterminated	Max cable length	Max cord length	Total max link length	Min box depth
2 Female RCA	5 m	2 m	9 m	50 mm

■ 4.2 Mechanical characteristics

Impact tests: IK 04
Penetration by solid bodies/liquid: IP 40

■ 4.3 Material characteristics

Base: Polycarbonate
Cover: ABS
Self-extinguishing: 650° C/30 s

■ 4.4 Climate characteristics

Usage temperature: +5°C to +35°C
Storage temperature: 0°C to +45°C

5. CLEANING

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.
Resistant to the following products:
Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.
Refer to e-catalogue.