



91850/2CE
91850/3CE
91850/4CE

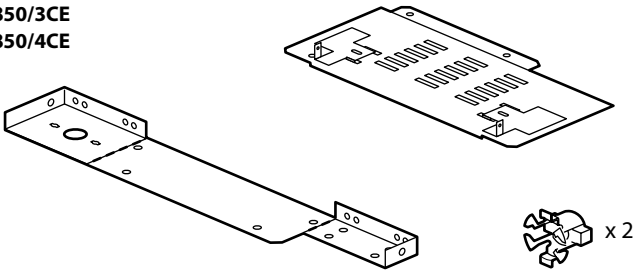


						M6 x 12
91850/2CE	x 1	x 1	x 1	x 2	x 9	x 19
91850/3CE	x 1	x 1	x 1	x 2	x 9	x 20
91850/4CE	x 2	x 2	x 2	x 4	x 17	x 30


91850/6SF
91850/8SF

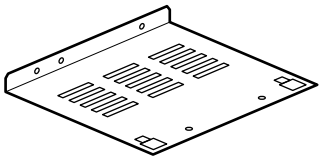


91850/6CV
91850/8CV

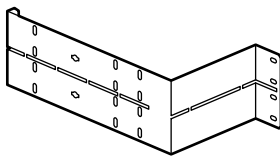

91850/CP

 

4b

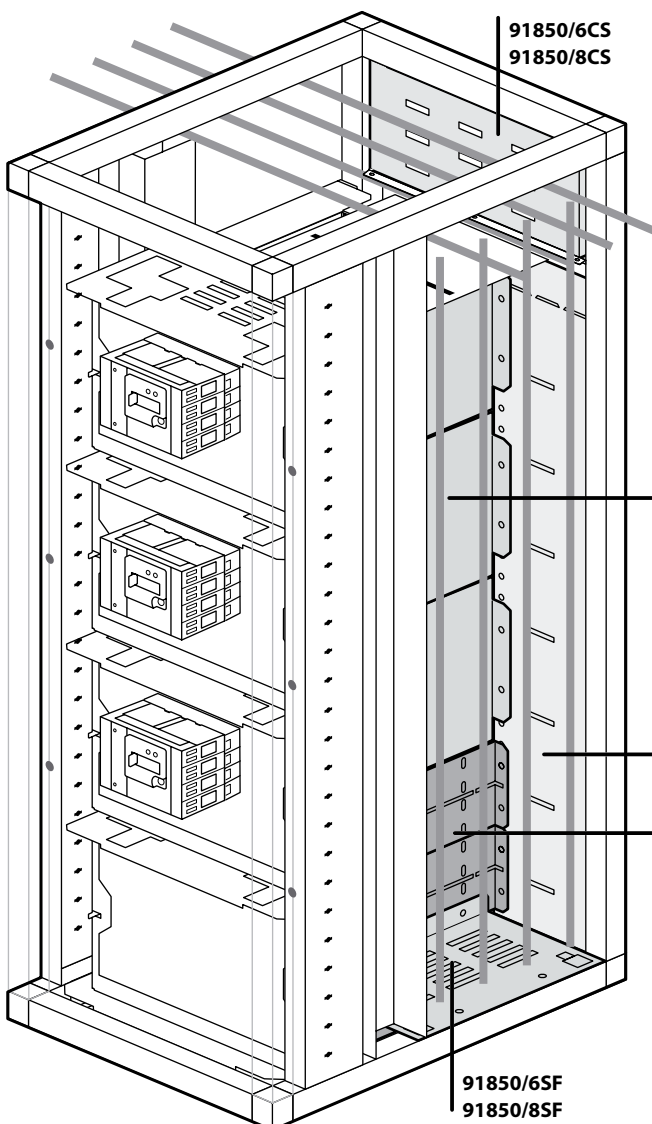


91850/6CS
91850/8CS

91850/2CE
91850/3CE
91850/4CE



91850/CP


91850/6CV
91850/8CV

91850/6SF
91850/8SF

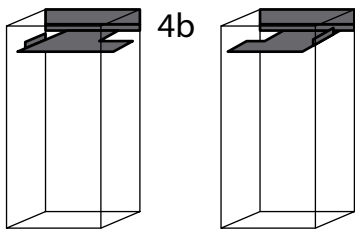






1600 A ↓ H = 200 mm	4000 A ↓ H = 300 mm	6300 A ↓ H = 400 mm

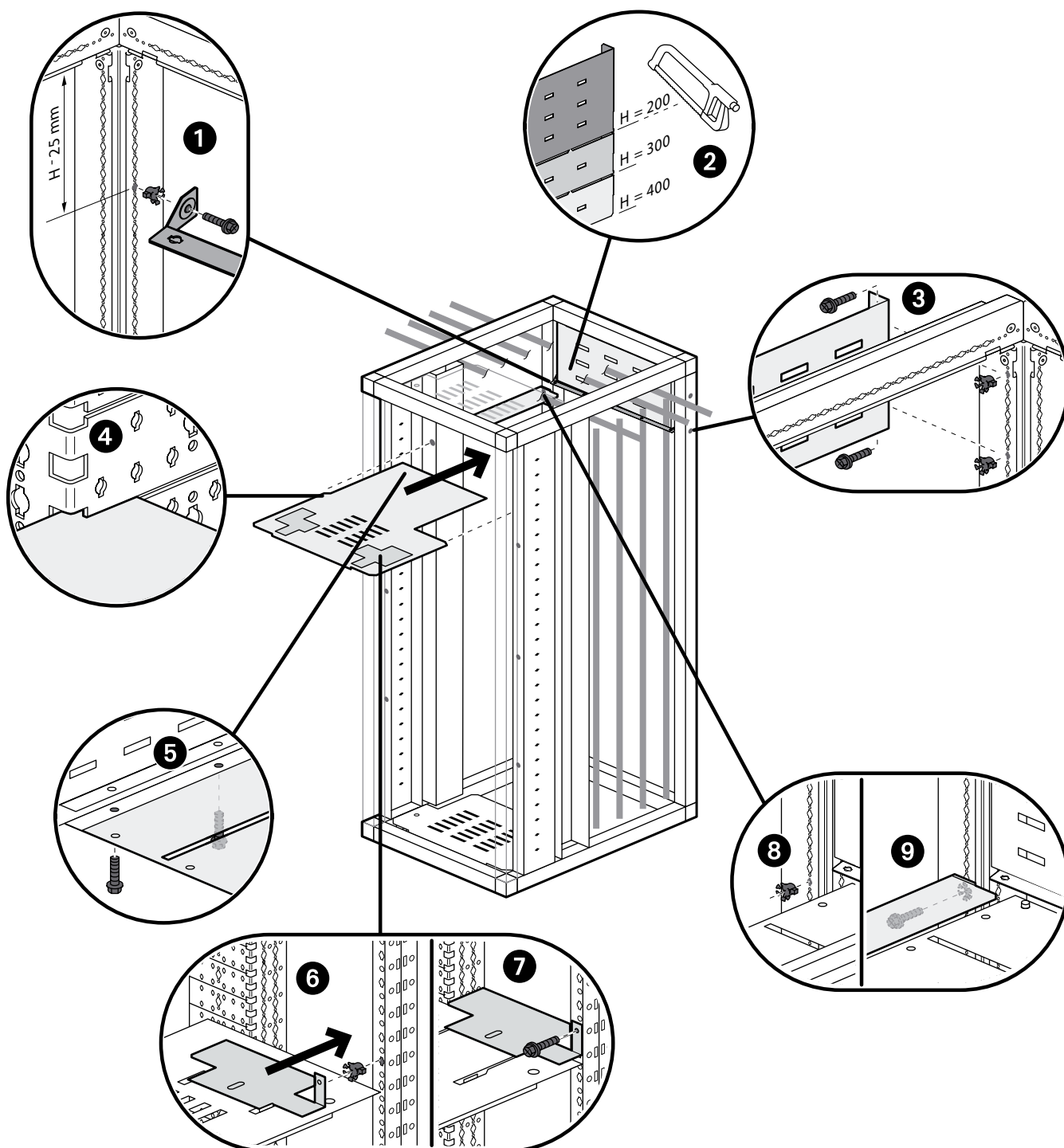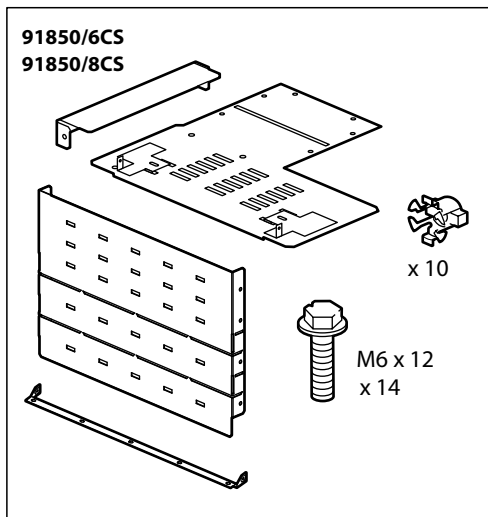







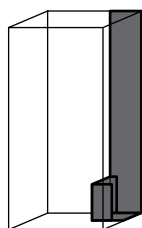



4b

91850/6SF
91850/8SF
91850/6CV
91850/8CV
91850/CP

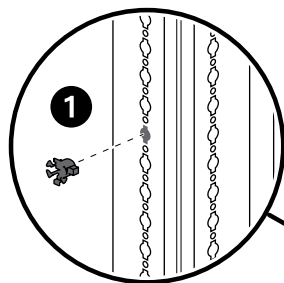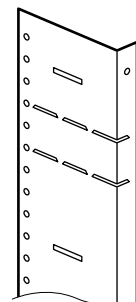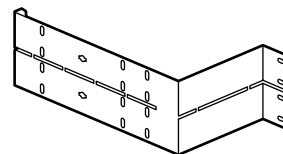
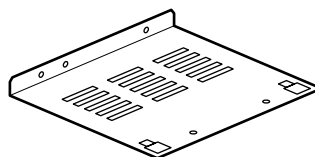
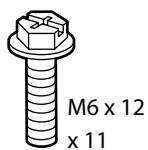


1600 A ↓ H = 200 mm	4000 A ↓ H = 300 mm	6300 A ↓ H = 400 mm

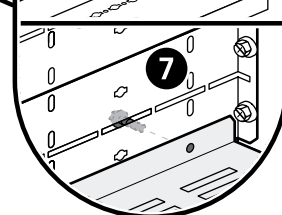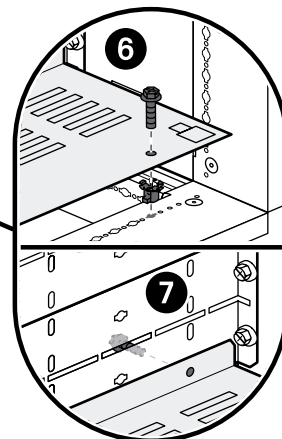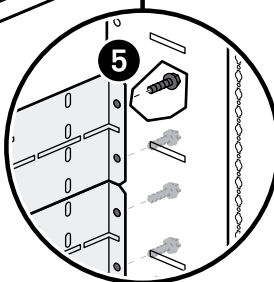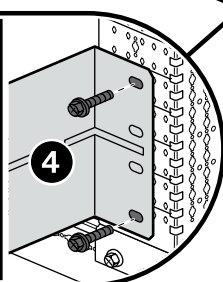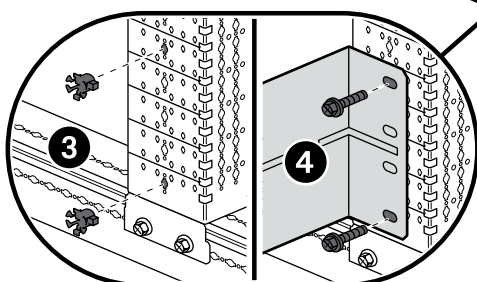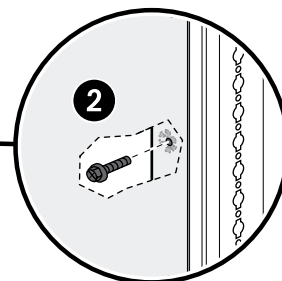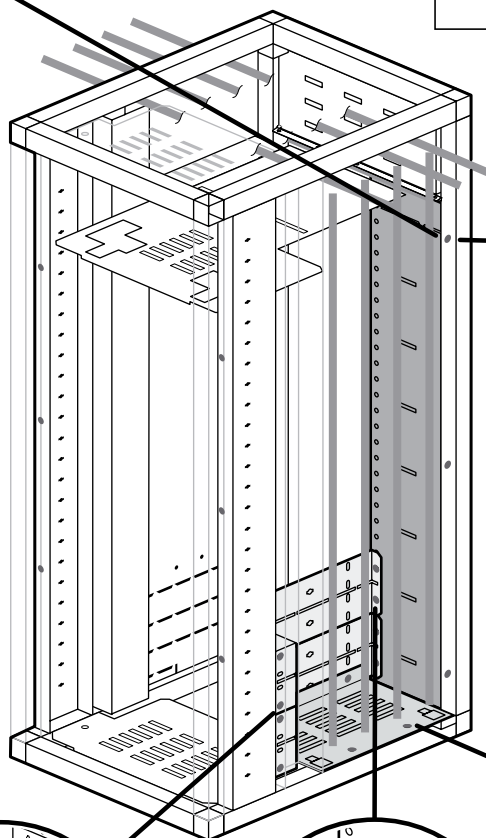

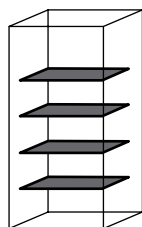


4b

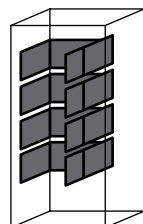
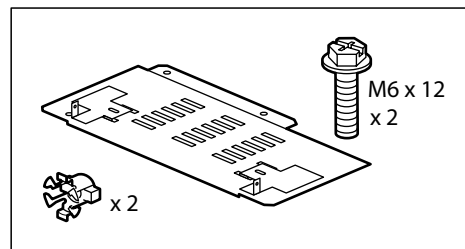
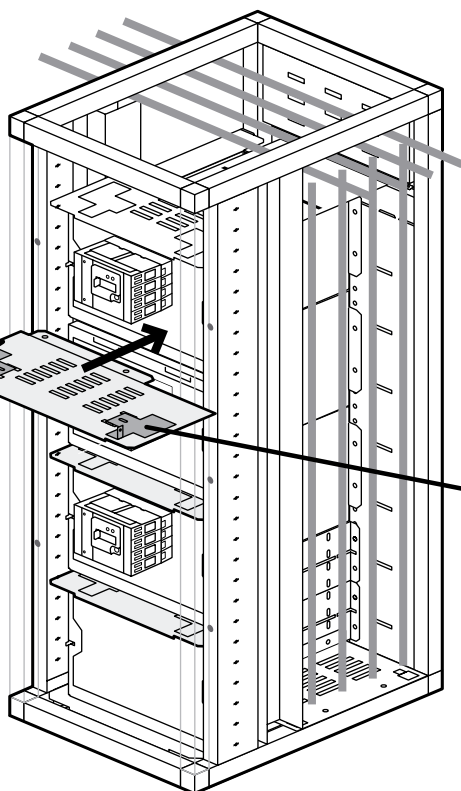


4b


91850/2CE
91850/3CE
91850/4CE

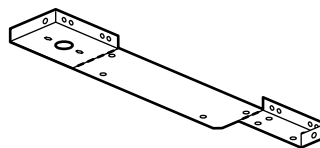


M6 x 12
91850/2CE x 17
91850/3CE x 18
91850/4CE x 30

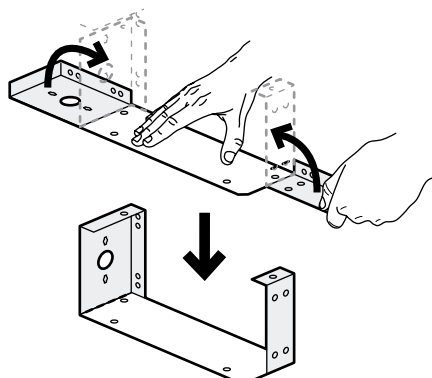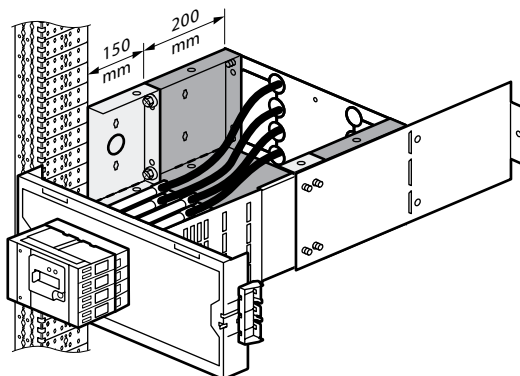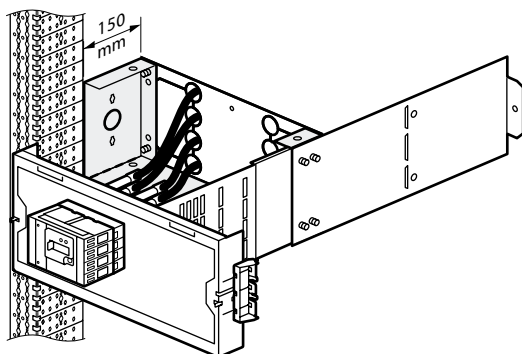

1

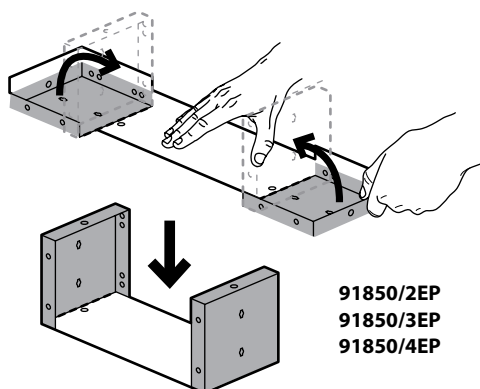









91850/2EP
91850/3EP
91850/4EP

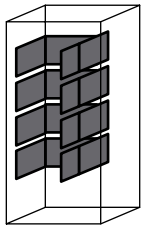


4b



91850/2CE x 9
91850/3CE x 9
91850/4CE x 17

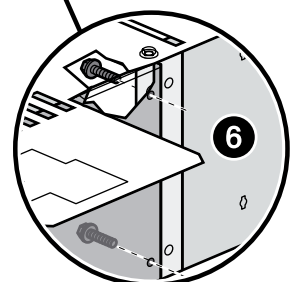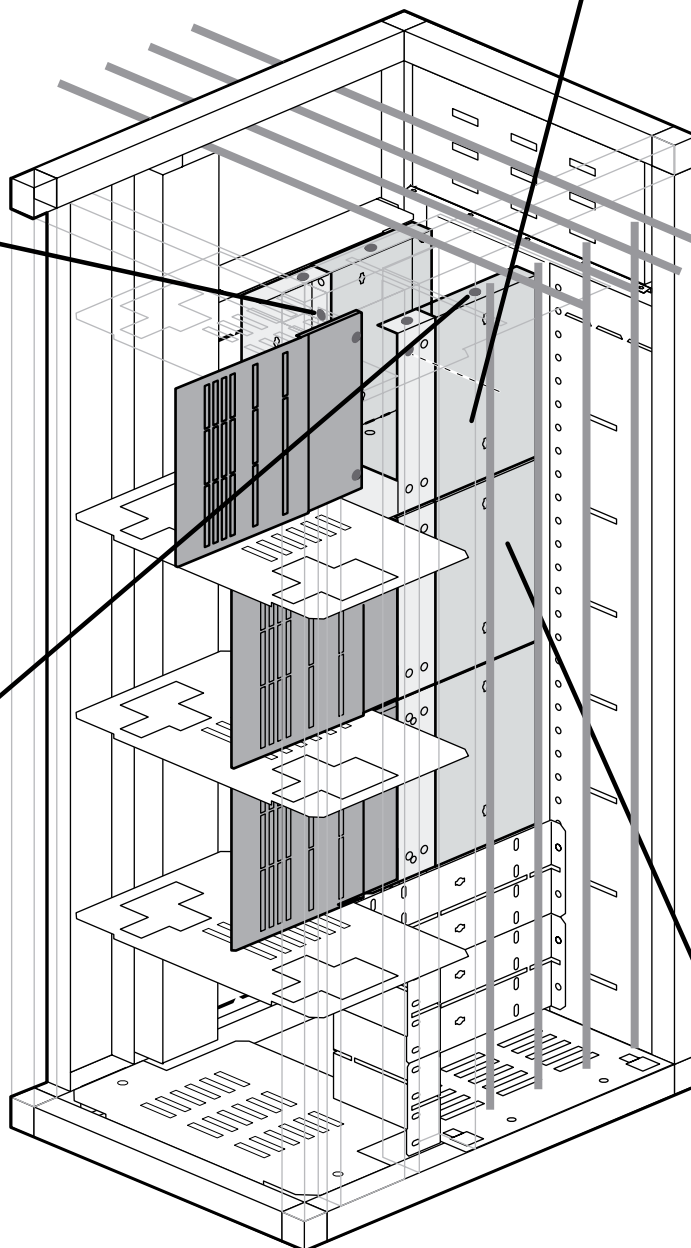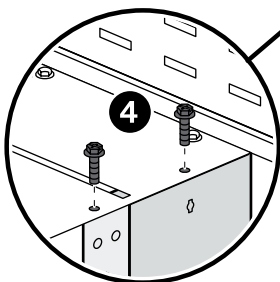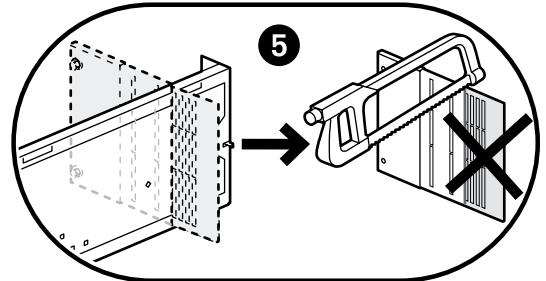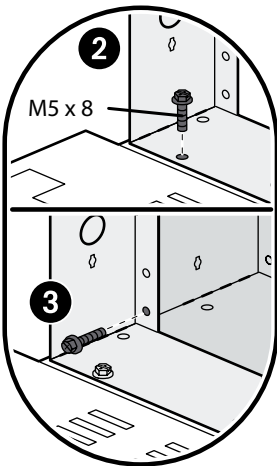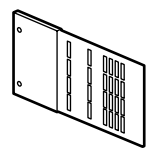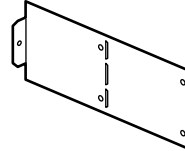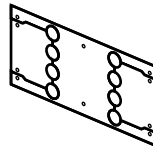

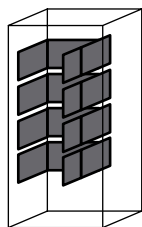

4b

