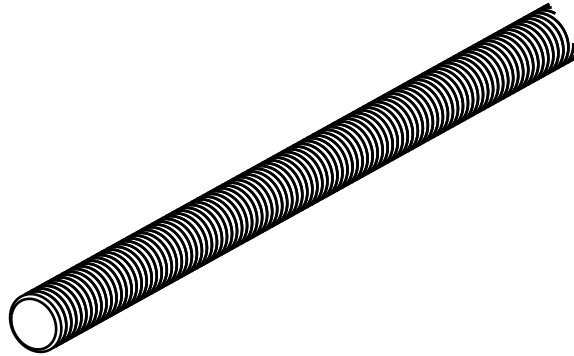


**TIGE FILETEE
THREADED ROD**

 Reference(s) : 801 701/04/11/14/21/24/31/34
350 456/57/58/59

1. GAMME / RANGE

Designation	Code	Poids / Weight		A	Classe/ Class	Norme / Standard	Finition / Coating	Classe de résistance contre la corrosion/ Resistance class against corrosion
		(Kg)	(lb)					
TF 6x1000 EZ	801 701	0.222	0.489	M6	4-8	ISO 898-1	EZ	Class 1 / IEC 61537
TF 6x1000 316L	801 704				A4	ISO 3506-1	IN316L / SS316L	Class 9D / IEC 61537
TF 6x1000 ZnNi	350 456				4-8	ISO 898-1	ZnNi	Class 8 / IEC 61537
TF 8x1000 EZ	801 711	0.395	0.871	M8	4-8	ISO 898-1	EZ	Class 1 / IEC 61537
TF 8x1000 316L	801 714				A4	ISO 3506-1	IN316L / SS316L	Class 9D / IEC 61537
TF 8x1000 ZnNi	350 457				4-8	ISO 898-1	ZnNi	Class 8 / IEC 61537
TF 10x1000 EZ	801 721	0.617	1.63	M10	4-8	ISO 898-1	EZ	Class 1 / IEC 61537
TF 10x1000 316L	801 724				A4	ISO 3506-1	IN316L / SS316L	Class 9D / IEC 61537
TF 10x1000 ZnNi	350 458				4-8	ISO 898-1	ZnNi	Class 8 / IEC 61537
TF 12x1000 EZ	801 731	0.888	1.958	M12	4-8	ISO 898-1	EZ	Class 1 / IEC 61537
TF 12x1000 316L	801 734				A4	ISO 3506-1	IN316L / SS316L	Class 9D / IEC 61537
TF 12x1000 ZnNi	350 459				4-8	ISO 898-1	ZnNi	Class 8 / IEC 61537

2. DIMENSIONS (mm/inch)
