


PROFIL U U 24 / 24 / 24
U SECTION U 24 / 24 / 24

INOX 316L

CABLOFIL®
INNOVATORS IN CABLE MANAGEMENT

FT0255-4

02 16

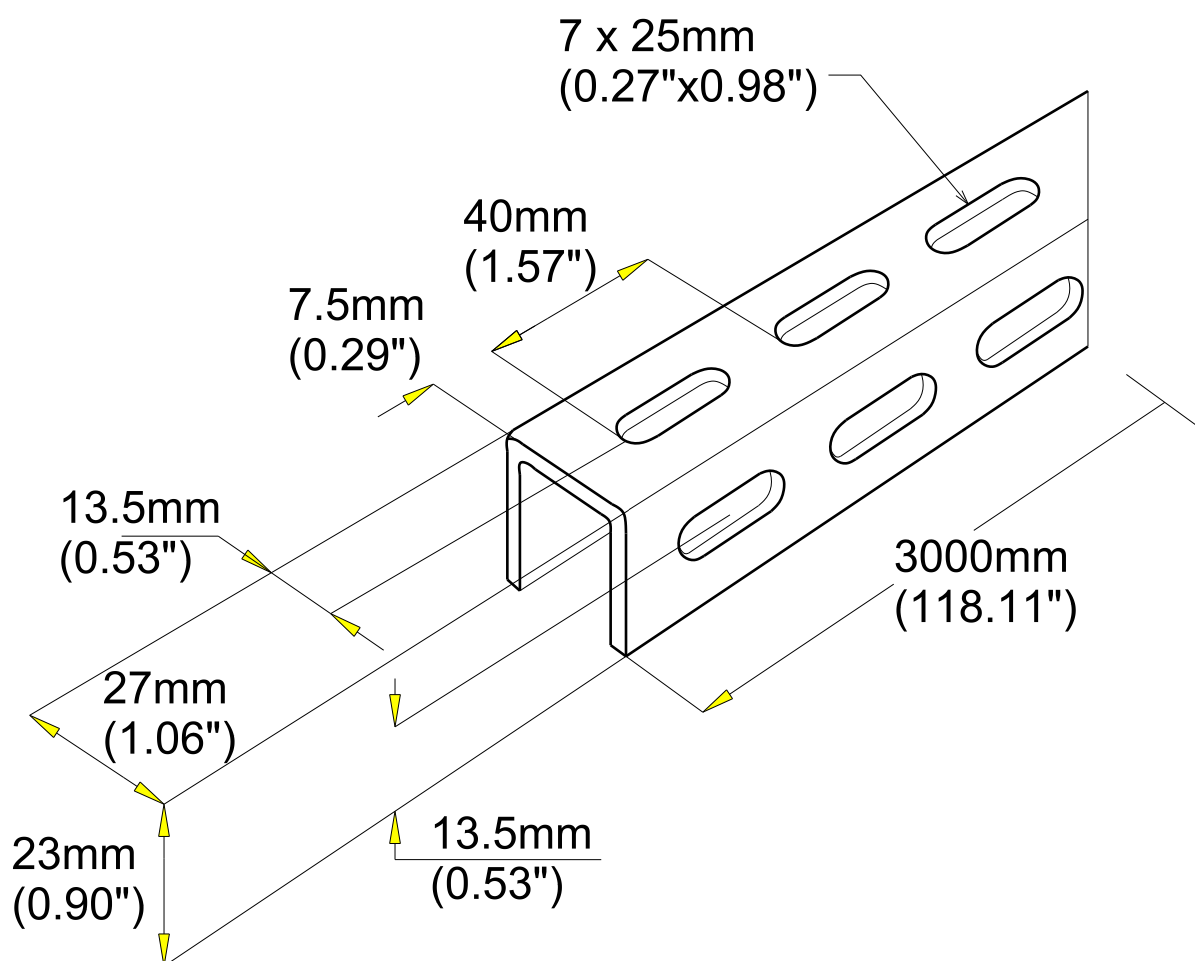

Material	Standard
X2 CrNiMo 17-12-2	EN 10088-2

REF	CODE	POIDS (Kg/m)	WEIGHT (lb/ft)
U24/24/24	923 204	0.600	0.404

EPAISSEUR / THICKNESS
1.5 / (0.06")