


## RE41 SP

Reference(s) : 595 700/703/750/780/790

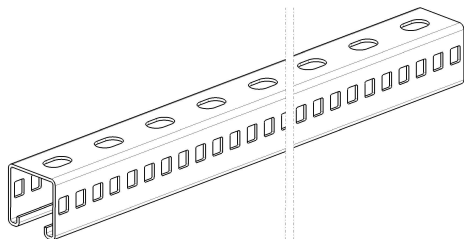

### 1 RANGE

| Designation | L     | Code   | Matière<br>Raw material | Norme<br>Standard | Finition<br>Coating | Norme<br>standard | Colisage<br>Packing | Masse<br>Weight<br>(KG/pcs) |
|-------------|-------|--------|-------------------------|-------------------|---------------------|-------------------|---------------------|-----------------------------|
| RE41 SP3000 | 3 000 | 595700 | DX 51 D Z275 MAC        | EN 10 346         | GS                  | -                 | 20                  | 5,076                       |
| RE41 SP3000 | 3 000 | 595703 | S 235 JR                | EN 10025          | GC                  | EN ISO 1461       | 20                  | 5,076                       |
| RE41 SP500  | 500   | 595750 | DX 51 D Z275 MAC        | EN 10 346         | GS                  | -                 | 10                  | 0,846                       |
| RE41 SP800  | 800   | 595780 | DX 51 D Z275 MAC        | EN 10 346         | GS                  | -                 | 120                 | 1,385                       |
| RE41 SP1000 | 1 000 | 595790 | DX 51 D Z275 MAC        | EN 10 346         | GS                  | -                 | 120                 | 1,692                       |

Epaisseur/Thickness(mm/Inch) = 2 / 0,08"

Dimensions in (mm/inch) :

