


COUDE 90° P31 FB H25 50 à 500  
Flat bend P31 25x50 to 500

GS  
PG

**CABLOFIL®**  
INNOVATORS IN CABLE MANAGEMENT

FT0587-0

04 18

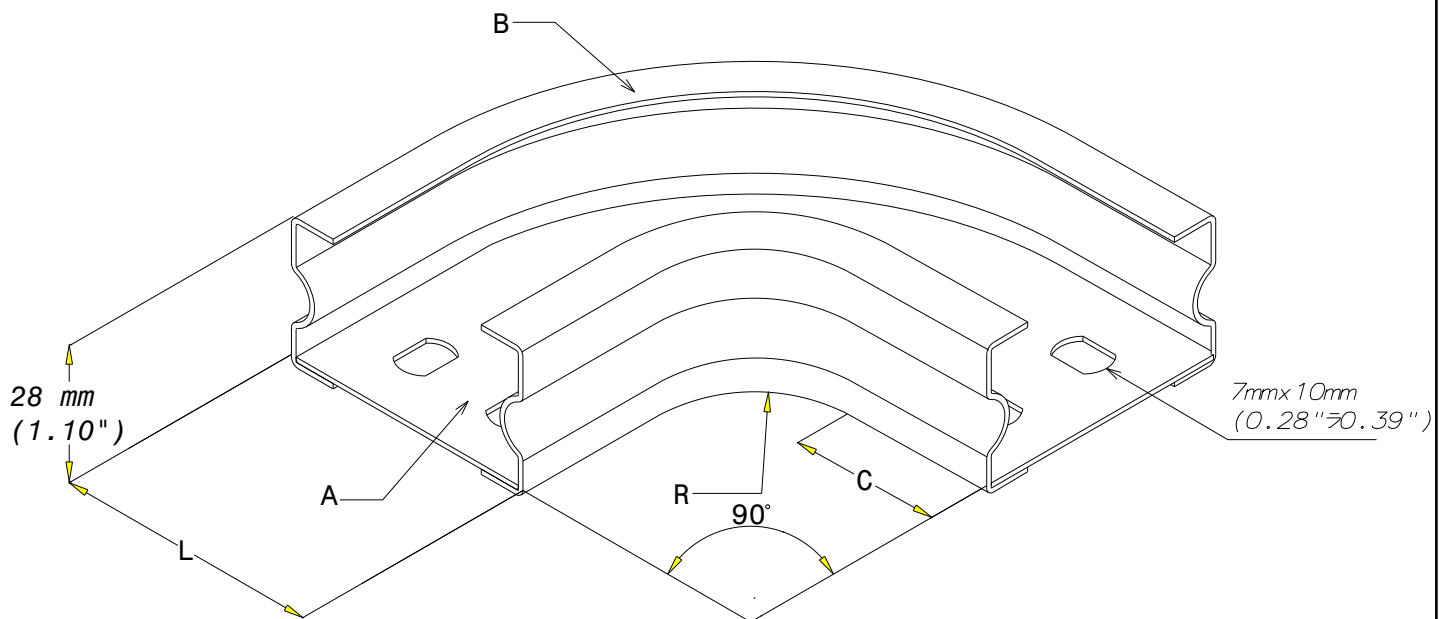

REF	CODE	L (mm)	L (inch)	A (mm)	A (inch)	B (mm)	B (inch)	C (mm)	C (inch)	R (mm)	R (inch)
P31 FB 25x50	340 906	50	(1.97")	0.8	(0.032")	1	(0.039")	30	(1.18")	20	(0.78")
P31 FB 25x75	340 907	77	(2.92")	0.8	(0.032")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB 25x100	340 908	100	(3.94")	0.8	(0.032")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB 25x150	340 909	150	(5.91")	0.8	(0.032")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB 25x200	340 910	200	(5.91")	0.8	(0.032")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB 25x300	340 911	300	(7.87")	1	(0.039")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB 25x400	340 912	400	(11.81")	1	(0.039")	1	(0.039")	50	(1.97")	150	(5.91")
P31 FB 25x500	340 913	500	(19.69")	1	(0.039")	1	(0.039")	50	(1.97")	150	(5.91")

NORMES  
STANDARD

MATIERE / MATERIAL  
DX 51 D Z 200 MAC  
PROTECTION / COATING  
Pregalvanised

EN 10 346