

COUDE 45° P31 FB H25 50 à 500
Flat bend P31 25x50 to 500



GS
PG

CABLOFIL®
INNOVATORS IN CABLE MANAGEMENT

FT0588-0

04 18

DÉTAIL P31 FB45 25/50

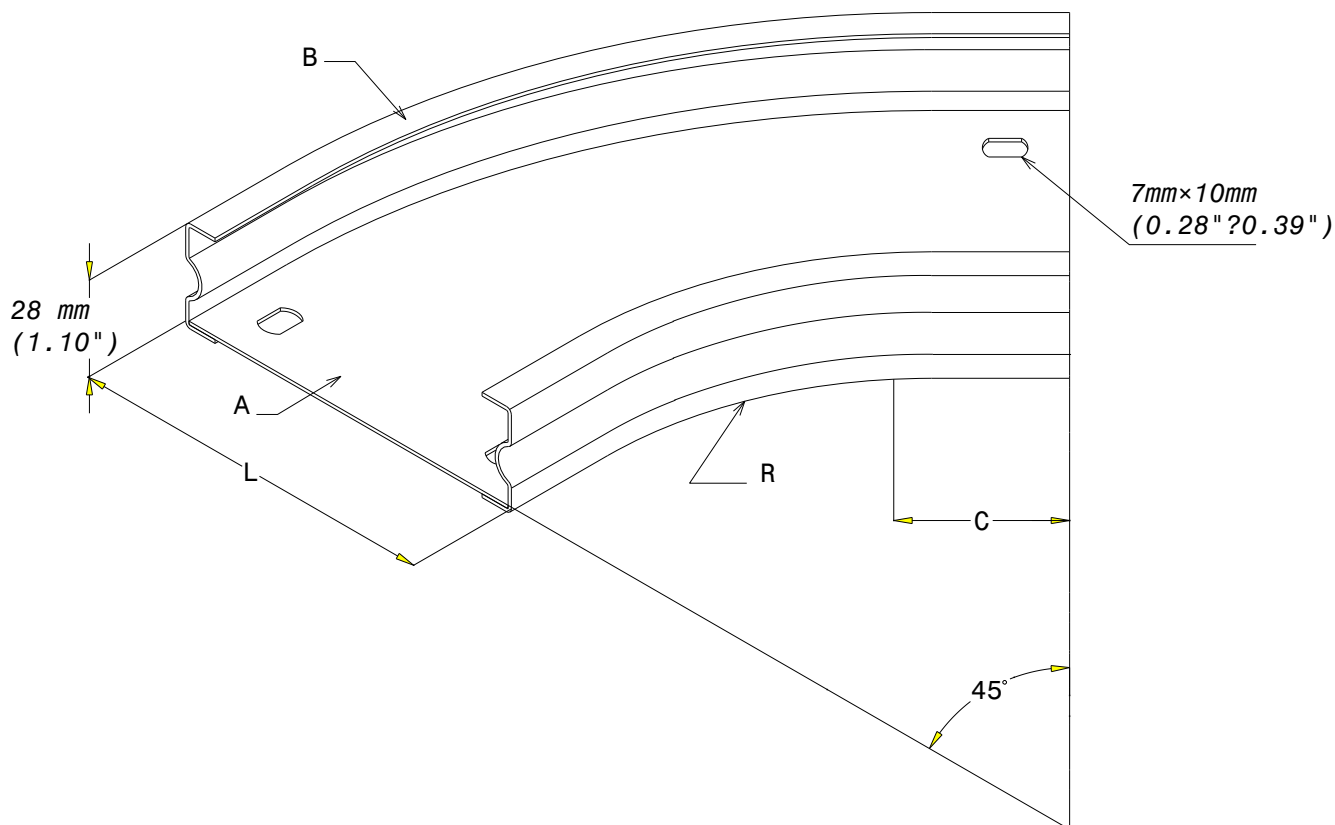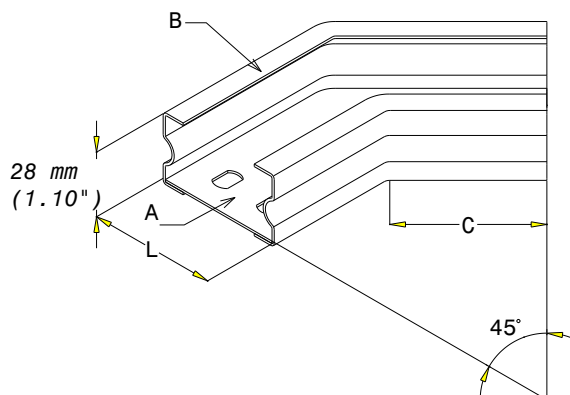

REF	CODE	L	/L	A	/A	B	/B	C	/C	R	/R
		(mm)	(inch)	(mm)	(inch)	(mm)	(inch)	(mm)	(inch)	(mm)	(inch)
P31 FB45 25x50	340 936	50	(1.97")	0.8	(0.032")	1	(0.039")	30	(1.18")	-	-
P31 FB45 25x75	340 937	77	(2.92")	0.8	(0.032")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB45 25x100	340 938	100	(3.94")	0.8	(0.032")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB45 25x150	340 939	150	(5.91")	0.8	(0.032")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB45 25x200	340 940	200	(7.87")	0.8	(0.032")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB45 25x300	340 941	300	(11.81")	1	(0.039")	1	(0.039")	30	(1.18")	100	(3.94")
P31 FB45 25x400	340 942	400	(15.75")	1	(0.039")	1	(0.039")	50	(1.97")	150	(5.91")
P31 FB45 25x500	340 943	500	(19.69")	1	(0.039")	1	(0.039")	50	(1.97")	150	(5.91")

NORMES
STANDARD

MATIERE / MATERIALE
DX 51 D Z 200 MAC

EN 10 346

PROTECTION / COATING
Pregalvanised