


CHT PL CONC P31 IR H25 50 à 500
Inside riser P31 25x50 to 500

GC
 HDG

CABLOFIL®

FT0594-4

09 11

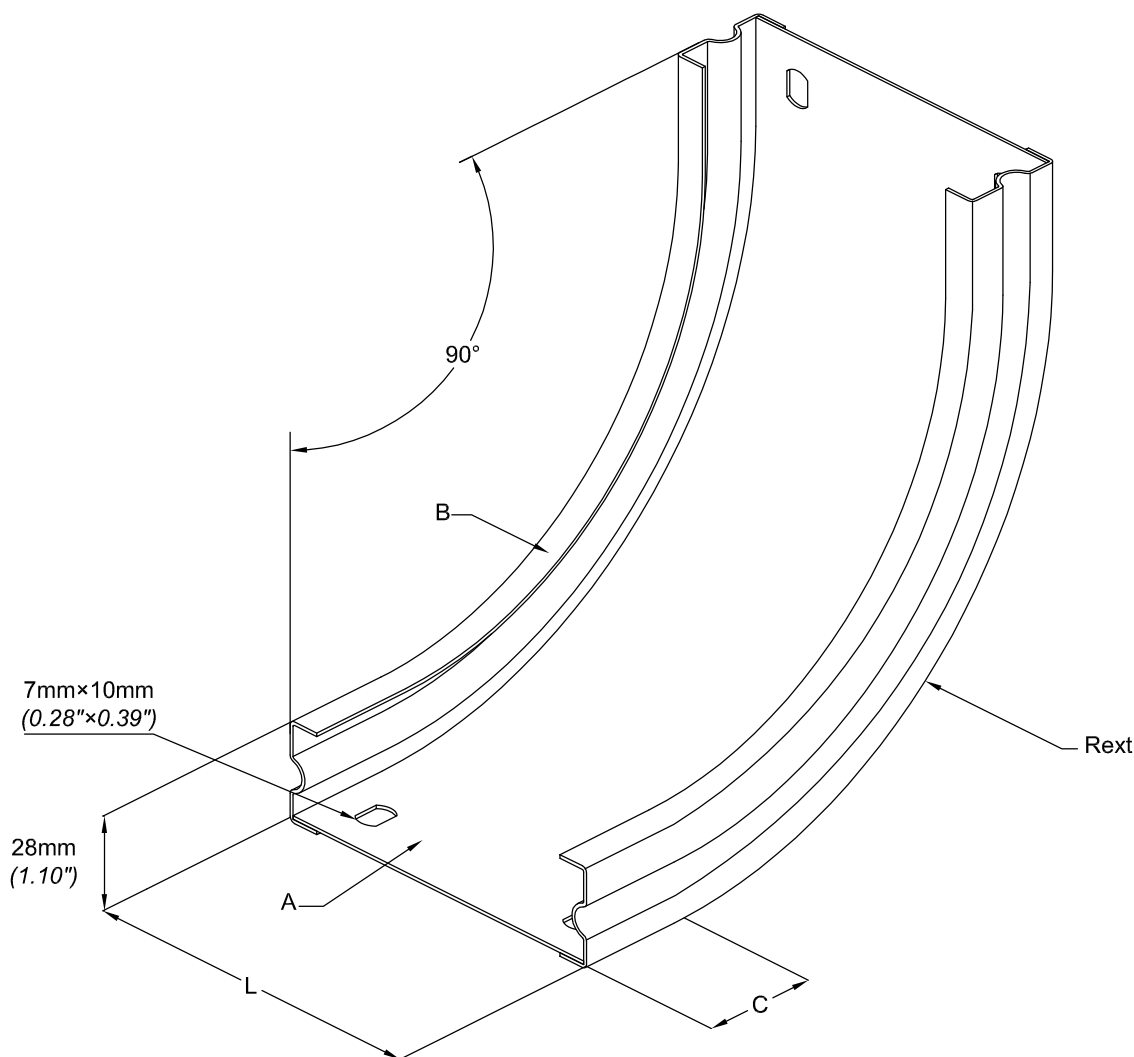

REF	CODE	L (mm) / L (Inch)		A (mm) / A (Inch)		B (mm) / B (Inch)		C (mm) / C (Inch)		R (mm) / R (Inch)	
P31 IR 25x50	342 971	50	(1.97")	0.8	(0.032")	1	(0.039")	30	(1.18")	48	(1.89")
P31 IR 25x75	342 972	75	(2.92")	0.8	(0.032")	1	(0.039")	30	(1.18")	128	(5.04")
P31 IR 25x100	342 973	100	(3.94")	0.8	(0.032")	1	(0.039")	30	(1.18")	128	(5.04")
P31 IR 25x150	342 974	150	(5.91")	0.8	(0.032")	1	(0.039")	30	(1.18")	128	(5.04")
P31 IR 25x200	342 975	200	(5.91")	0.8	(0.032")	1	(0.039")	30	(1.18")	128	(5.04")
P31 IR 25x300	342 976	300	(7.87")	1	(0.039")	1	(0.039")	30	(1.18")	128	(5.04")
P31 IR 25x400	342 977	400	(11.81")	1	(0.039")	1	(0.039")	50	(1.97")	178	(7.01")
P31 IR 25x500	342 978	500	(19.69")	1	(0.039")	1	(0.039")	50	(1.97")	178	(7.01")

NORMES / STANDARD

MATIERE / MATERIAL
 S 235 JR

EN 10 025

PROTECTION / COATING
 Geomet 500 Grade A

Propriété exclusive de CABLOFIL, ne peut être ni copié, ni transmis à des tiers sans autorisation écrite.

Exclusive property of CABLOFIL shouldn't be reproduced or transmitted to any people without written authorization