

COUDE 45 ° P31 FB45 H100 100 à 600
 FLAT BEND 45 ° P31 100x100 to 600


GS
 PG



CABLE
 MANAGEMENT

FT0604-0

10 16

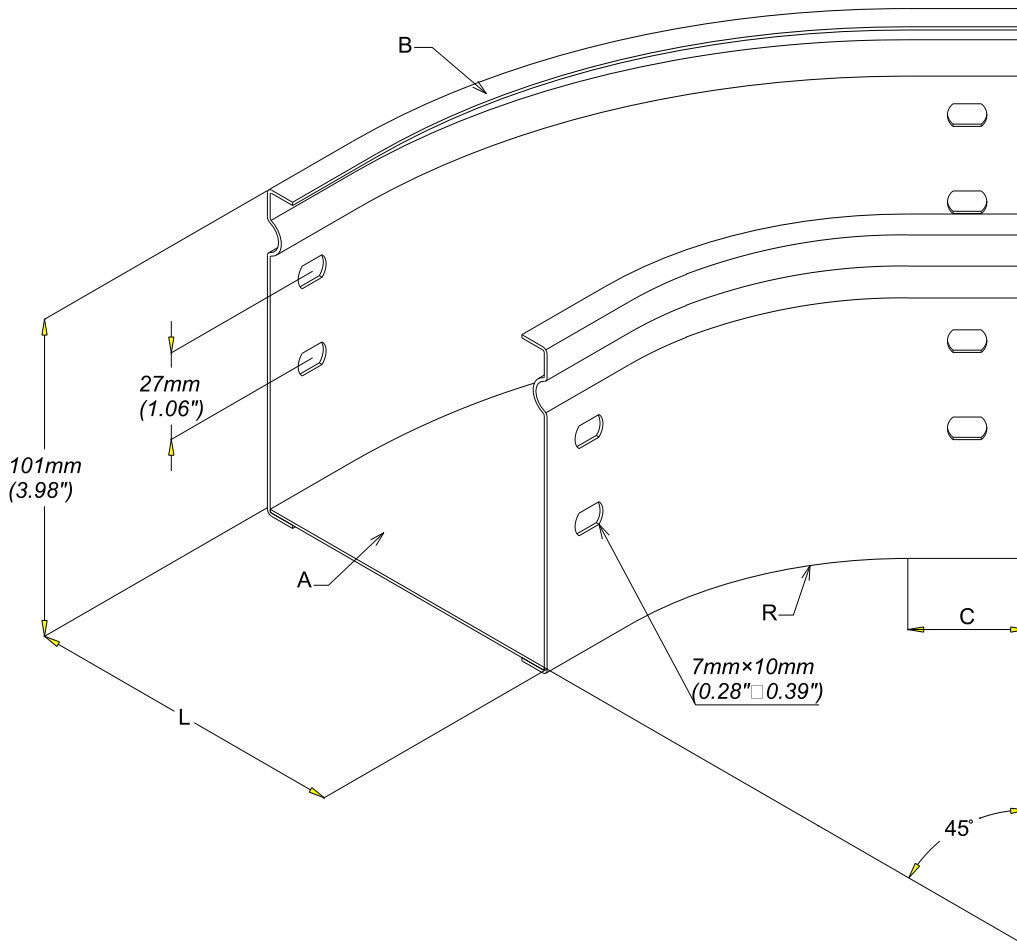

REF	CODE	L /L		A /A		B /B		C /C		R /R	
		(mm)	(inch)	(mm)	(inch)	(mm)	(inch)	(mm)	(inch)	(mm)	(inch)
P31 FB45 100x100	340 960	100	(3.94")	0.8	(0.032")	0.95	(0.037")	30	(1.18")	100	(3.94")
P31 FB45 100x150	340 961	150	(5.91")	0.8	(0.032")	0.95	(0.037")	30	(1.18")	100	(3.94")
P31 FB45 100x200	340 962	200	(7.87")	0.8	(0.032")	0.95	(0.037")	30	(1.18")	100	(3.94")
P31 FB45 100x300	340 963	300	(11.81")	1	(0.039")	0.95	(0.037")	30	(1.18")	100	(3.94")
P31 FB45 100x400	340 964	400	(15.75")	1	(0.039")	0.95	(0.037")	50	(1.97")	150	(5.91")
P31 FB45 100x500	340 965	500	(19.69")	1	(0.039")	0.95	(0.037")	50	(1.97")	150	(5.91")
P31 FB45 100x600	350 512	600	(23.62")	1	(0.039")	0.95	(0.037")	50	(1.97")	150	(5.91")

Material	Standard
DX 51 D Z 200 MAC	EN 10 346

Propriété exclusive de LEGRAND, ne peut être ni copié, ni transmis à des tiers sans autorisation écrite.

Exclusive property of LEGRAND shouldn't be reproduced or transmitted to any people without written authorization