



EAC GLO4L60
EAC GLO4L60

GS
PREGALV

CABLOFIL®
INNOVATORS IN CABLE MANAGEMENT

FT0640-0

08 06

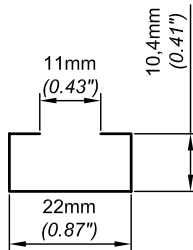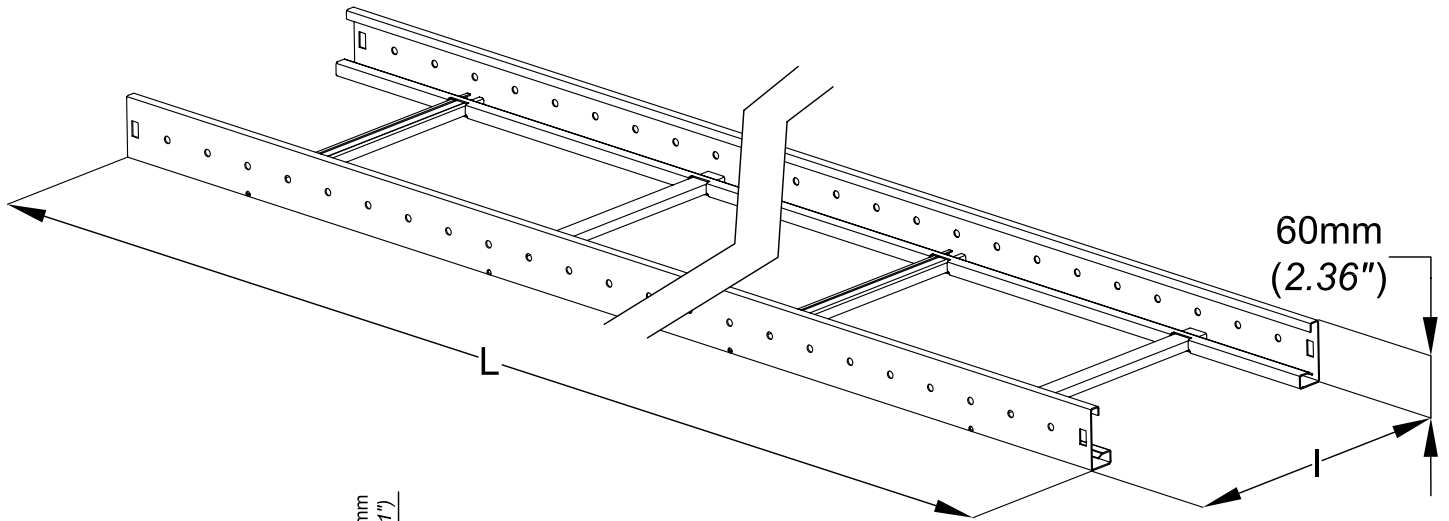

Version light
(Light version)



Renforts alternés
(reinforcement alternated)

REF	CODE	L (mm)	L (inch)	l (mm)	l (inch)	Poids (kg)	Weight (lb)
GLO4L60/3/200	83 111 32	3000	118,2	200	7,88	8,20	18,16
GLO4L60/3/300	83 111 33	3000	118,2	300	11,82	8,60	19,04
GLO4L60/3/400	83 111 34	3000	118,2	400	15,76	9,10	20,15
GLO4L60/3/500	83 111 35	3000	118,2	500	19,70	9,51	21,05
GLO4L60/3/600	83 111 36	3000	118,2	600	23,64	9,90	21,92
GLO4L60/6/200	83 111 62	6000	236,4	200	7,88	15,87	35,14
GLO4L60/6/300	83 111 63	6000	236,4	300	11,82	16,71	36,99
GLO4L60/6/400	83 111 64	6000	236,4	400	15,76	17,56	38,87
GLO4L60/6/500	83 111 65	6000	236,4	500	19,70	19,01	42,10
GLO4L60/6/600	83 111 66	6000	236,4	600	23,64	21,00	46,50

NORMES / STANDARD

MATIERE / MATERIAL DX 51 D Z235 MAC	EN 10327
PROTECTION / COATING GS / PREGALV	EN 10327

Epaisseur / Thickness
1,25mm / 0.049"

Propriété exclusive de CABLOFIL, ne peut être ni copié, ni transmis à des tiers sans autorisation écrite.

Exclusive property of CABLOFIL shouldn't be reproduced or transmitted to any people without written authorization