


CP SFS GLO4
CP SFS GLO4

GS
HDG

CABLOFIL
INNOVATORS IN CABLE MANAGEMENT

FT0650-0

08 03

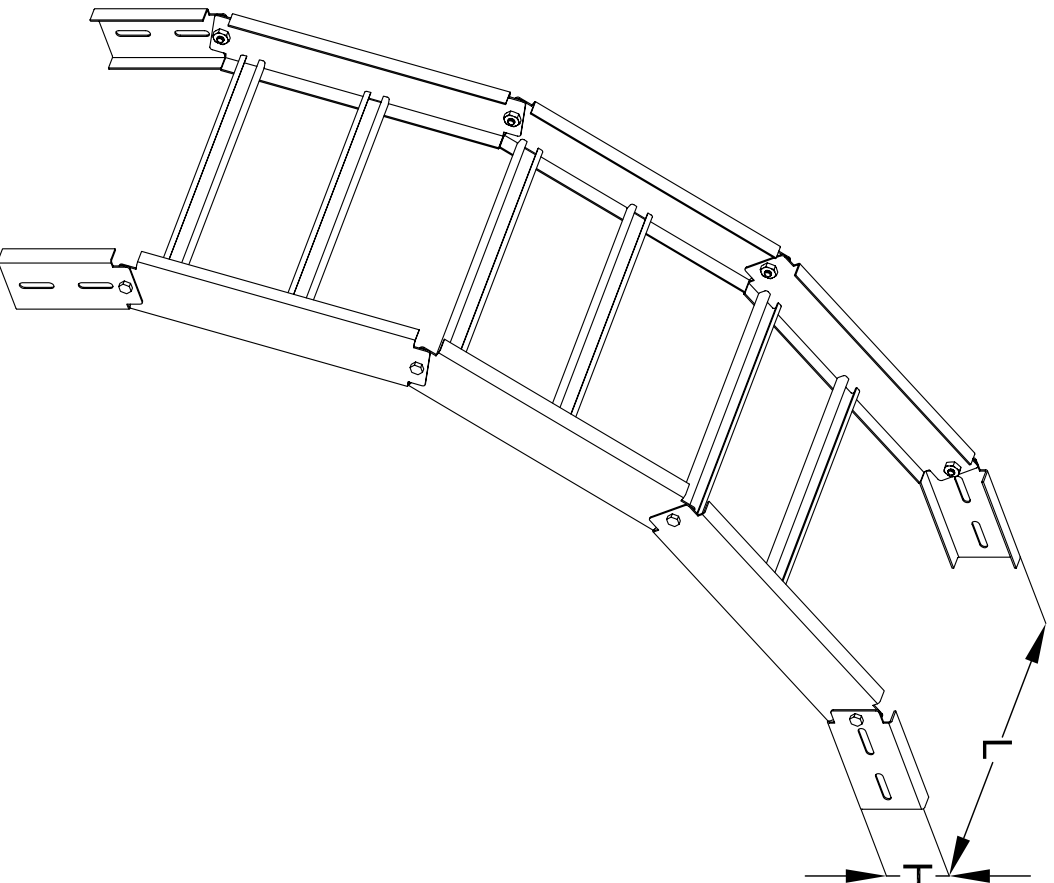

REF	CODE	L (mm)	L (inch)	H (mm)	H (inch)	Poids(kg)	Weight(lb)
SFS GLO4L60/200	83 121 52	200	7.88	60	2.36	2.9	6.42
SFS GLO4L60/300	83 121 53	300	11.82	60	2.36	3.39	7.506
SFS GLO4L60/400	83 121 54	400	15.76	60	2.36	3.85	8.524
SFS GLO4L60/500	83 121 55	500	19.70	60	2.36	4.37	9.675
SFS GLO4L60/600	83 121 56	600	23.64	60	2.36	4.83	10.694
SFS GLO4L100/200	83 122 52	200	7.88	100	3.94	3.60	7.969
SFS GLO4L100/300	83 122 53	300	11.82	100	3.94	3.89	8.611
SFS GLO4L100/400	83 122 54	400	15.76	100	3.94	4.18	9.265
SFS GLO4L100/500	83 122 55	500	19.70	100	3.94	4.47	9.897
SFS GLO4L100/600	83 122 56	600	23.64	100	3.94	5.181	11.471
SFS GLO4M100/200	83 125 52	200	7.88	100	3.94	4.104	9.085
SFS GLO4M100/300	83 125 53	300	11.82	100	3.94	4.644	10.282
SFS GLO4M100/400	83 125 54	400	15.76	100	3.94	5.184	11.478
SFS GLO4M100/500	83 125 55	500	19.70	100	3.94	5.832	12.912
SFS GLO4M100/600	83 125 56	600	23.64	100	3.94	6.372	14.108

NORMES / STANDARD

MATIERE / MATERIAL
DX 51 D Z235 MAC EN 10327

PROTECTION / COATING
GS / Pregalv. EN 10327

Epaisseur / Thickness
1,25mm / 0.049"

Propriété exclusive de CABLOFIL, ne peut être ni copié, ni transmis à des tiers sans autorisation écrite.

Exclusive property of CABLOFIL shouldn't be reproduced or transmitted to any people without written authorization