


## P31 CO 3M IN316L

Reference(s) : 346 613/614/615/616/617/612/777/778

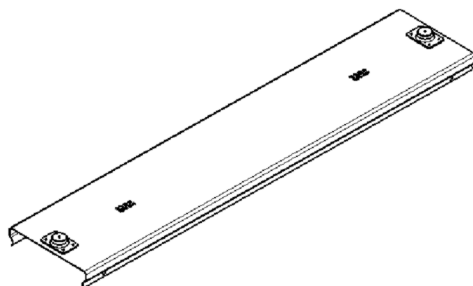

### 1 RANGE

Ref	Code	Matière Raw material	Norme Standard	Finition Coating	Masse Weight (Kg / Lb)	Epaisseur Thickness (mm/Inch)	w (mm / inch)
P31 CO 75 3M IN316L	346613	AISI 316L	EN 10088-2	SS316L	1,38 / 3,03	0,5 / 0,019"	75 / 2,95
P31 CO 100 3M IN316L	346614	AISI 316L	EN 10088-2	SS316L	1,65 / 3,63	0,5 / 0,019"	100 / 3,93"
P31 CO 150 3M IN316L	346615	AISI 316L	EN 10088-2	SS316L	2,24 / 4,92	0,5 / 0,019"	150 / 5,90"
P31 CO 200 3M IN316L	346616	AISI 316L	EN 10088-2	SS316L	2,82 / 6,21	0,5 / 0,019"	200 / 7,87"
P31 CO 300 3M IN316L	346617	AISI 316L	EN 10088-2	SS316L	4,8 / 10,56	0,6 / 0,023"	300 / 11,81"
P31 CO 400 3M IN316L	346612	AISI 316L	EN 10088-2	SS316L	7,77 / 17,09	0,8 / 0,031"	400 / 15,74"
P31 CO 500 3M IN316L	346777	AISI 316L	EN 10088-2	SS316L	9,54 / 20,98	0,8 / 0,031"	500 / 19,68"
P31 CO 600 3M IN316L	346778	AISI 316L	EN 10088-2	SS316L	11,3 / 24,86	0,8 / 0,031"	600 / 23,62"

Dimensions :

