


## P31 SF IN316L

Reference(s) : 346 900/901/902/903

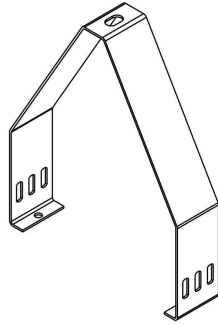

### 1 RANGE

Ref	Code	Matière Raw material	Norme Standard	Finition Coating	Masse Weight (Kg / Lb)	Epaisseur Thickness (mm/Inch)	w (mm / inch)
P31 SF L100 IN316L	346900	AISI 316L	EN 10088-2	SS316L	0,43 / 0,95	2 / 0,08"	100 / 3,94"
P31 SF L200 IN316L	346901	AISI 316L	EN 10088-2	SS316L	0,47 / 1,03	2 / 0,08"	200 / 7,87"
P31 SF L300 IN316L	346902	AISI 316L	EN 10088-2	SS316L	0,51 / 1,12	2 / 0,08"	300 / 11,81"
P31 SF L400 IN316L	346903	AISI 316L	EN 10088-2	SS316L	0,56 / 1,23	2 / 0,08"	400 / 15,75"

Dimensions :

