


PROFILE R21S

Reference(s) : 342180 – 342183 – 348040 – 348041 – 348042 – 348043 – 348044 – 348045 – 348046 – 348047 – 348340 – 348341 – 348342 – 348343 – 348344- 348345 – 348346 – 348347

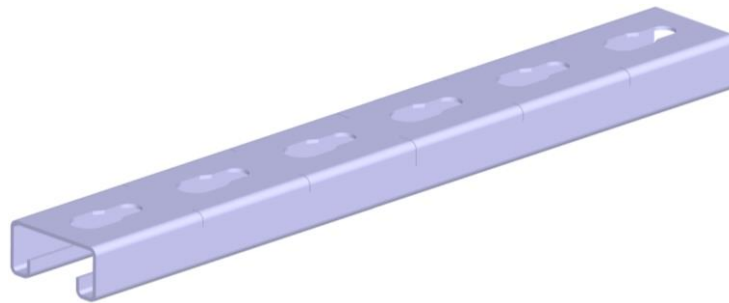

1 RANGE

Ref	Code	Matière Raw material	Norme standard	Finition Coating	Norme standard	Epaisseur Thickness (mm / Inch)	L Longueur Length (mm / Inch)	Masse Weight (KG / lb)
Profile R21S 200 HDG	348 342	S 235 JR	EN 10 025	HDG	NF EN ISO 1461	1,5 / 0,059	200 / 7,87	0,242 / 0,53
Profile R21S 300 HDG	348 343	S 235 JR	EN 10 025	HDG	NF EN ISO 1461	1,5 / 0,059	300 / 11,81	0,363 / 0,80
Profile R21S 400 HDG	348 344	S 235 JR	EN 10 025	HDG	NF EN ISO 1461	1,5 / 0,059	400 / 15,75	0,484 / 1,07
Profile R21S 500 HDG	348 345	S 235 JR	EN 10 025	HDG	NF EN ISO 1461	1,5 / 0,059	500 / 19,68	0,605 / 1,33
Profile R21S 600 HDG	348 346	S 235 JR	EN 10 025	HDG	NF EN ISO 1461	1,5 / 0,059	600 / 23,62	0,726 / 1,60
Profile R21S 700 HDG	348 347	S 235 JR	EN 10 025	HDG	NF EN ISO 1461	1,5 / 0,059	700 / 27,56	0,847 / 1,87
Profile R21S 1000 HDG	348 340	S 235 JR	EN 10 025	HDG	NF EN ISO 1461	1,5 / 0,059	1000 / 39,37	1,210 / 2,67
Profile R21S 2000 HDG	348 341	S 235 JR	EN 10 025	HDG	NF EN ISO 1461	1,5 / 0,059	2000 / 78,74	2,420 / 5,34
Profile R21S 3000 HDG	342 183	S 235 JR	EN 10 025	HDG	NF EN ISO 1461	1,5 / 0,059	3000 / 118,11	3,630 / 8,00
Profile R21S 200 PG	348 042	S250GD Z275 MAC	EN 10 346	GS	/	1,5 / 0,059	200 / 7,87	0,226 / 0,50
Profile R21S 300 PG	348 043	S250GD Z275 MAC	EN 10 346	GS	/	1,5 / 0,059	300 / 11,81	0,339 / 0,75
Profile R21S 400 PG	348 044	S250GD Z275 MAC	EN 10 346	GS	/	1,5 / 0,059	400 / 15,75	0,452 / 1,00
Profile R21S 500 PG	348 045	S250GD Z275 MAC	EN 10 346	GS	/	1,5 / 0,059	500 / 19,68	0,565 / 1,25
Profile R21S 600 PG	348 046	S250GD Z275 MAC	EN 10 346	GS	/	1,5 / 0,059	600 / 23,62	0,678 / 1,49
Profile R21S 700 PG	348 047	S250GD Z275 MAC	EN 10 346	GS	/	1,5 / 0,059	700 / 27,56	0,791 / 1,74
Profile R21S 1000 PG	348 040	S250GD Z275 MAC	EN 10 346	GS	/	1,5 / 0,059	1000 / 39,37	1,131 / 2,49
Profile R21S 2000 PG	348 041	S250GD Z275 MAC	EN 10 346	GS	/	1,5 / 0,059	2000 / 78,74	2,262 / 4,99
Profile R21S 3000 PG	342 180	S250GD Z275 MAC	EN 10 346	GS	/	1,5 / 0,059	3000 / 118,11	3,394 / 7,48

Dimensions in (mm/Inch) :

