


**PROFILE U60 HDG**

Reference(s) : 348378 – 348379

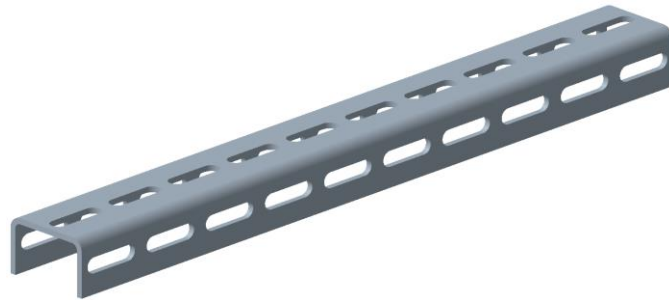

**1 RANGE**

Ref	Code	Matière Raw material	Norme Standard	Finition Coating	Norme standard	RAIL Epaisseur Thickness (mm / Inch)	L Longueur Length (mm / Inch)	Masse / Weight (KG / lb)
Profile U60 L3000 HDG	348 378	S235 JR	EN 10025	HDG	NF EN ISO 1461	4 / 0,157"	3000 / 118,11"	10,300 / 22,71
Profile U60 L4500 HDG	348 379	S235 JR	EN 10025	HDG	NF EN ISO 1461	4 / 0,157"	4500 / 177,17"	15,460 / 34,08

Dimensions in (mm/Inch) :

