 

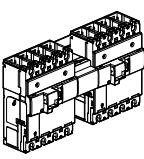
 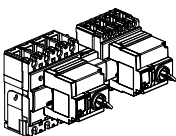

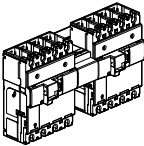
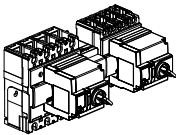
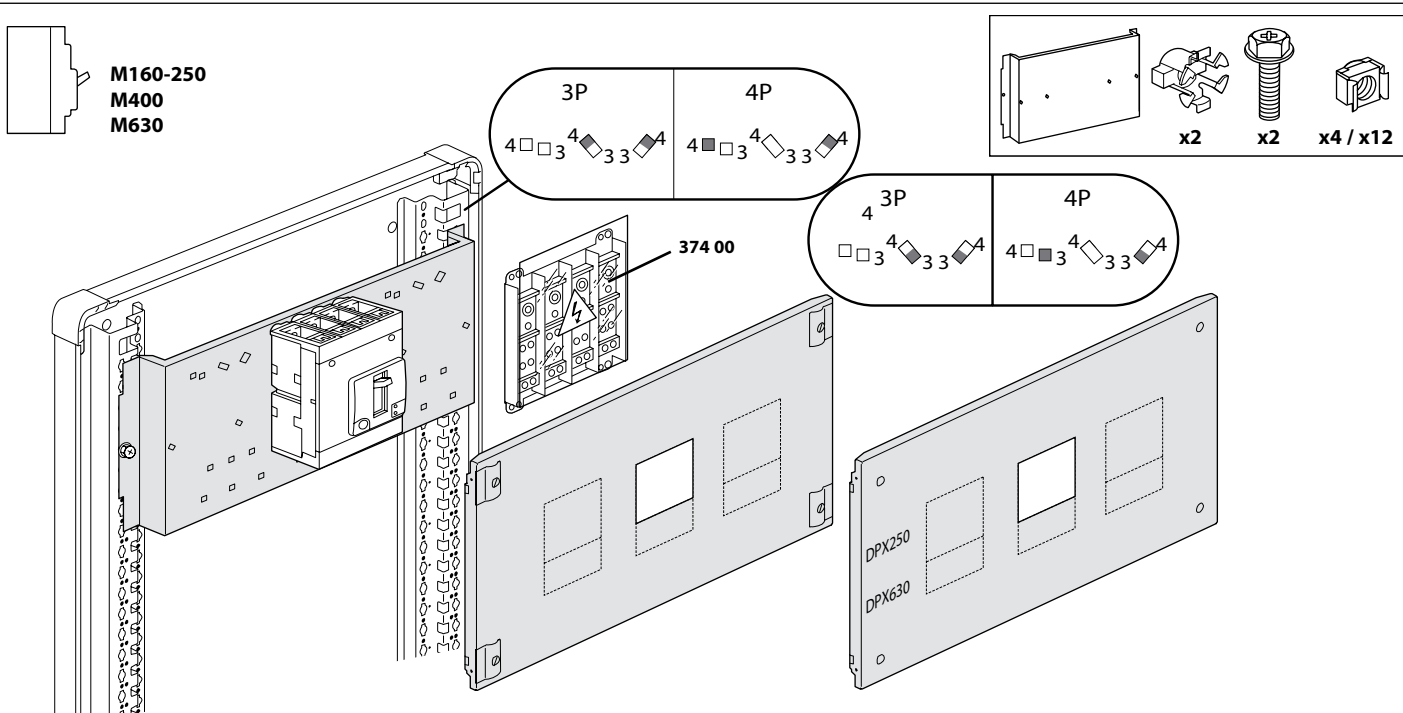
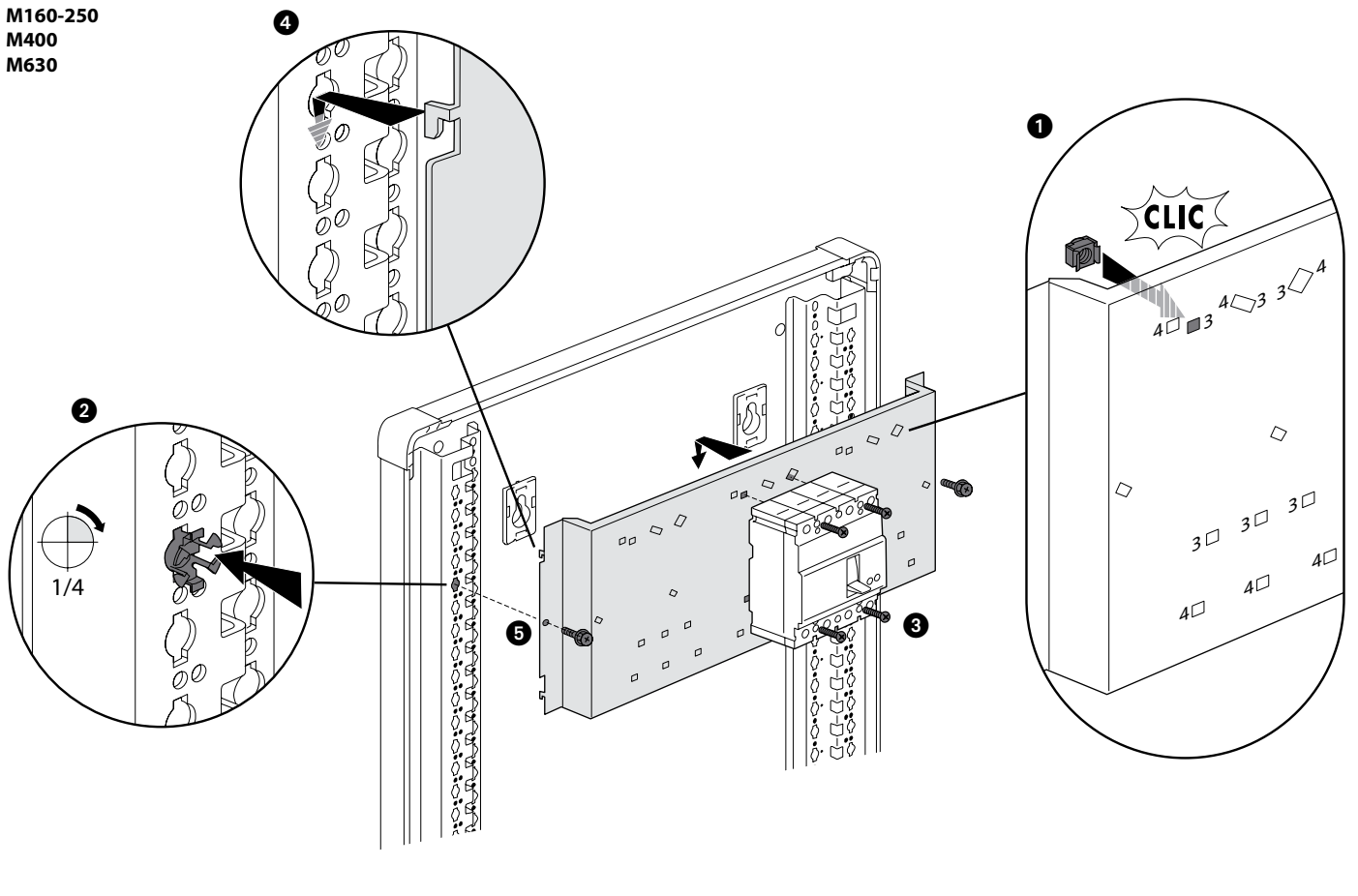
 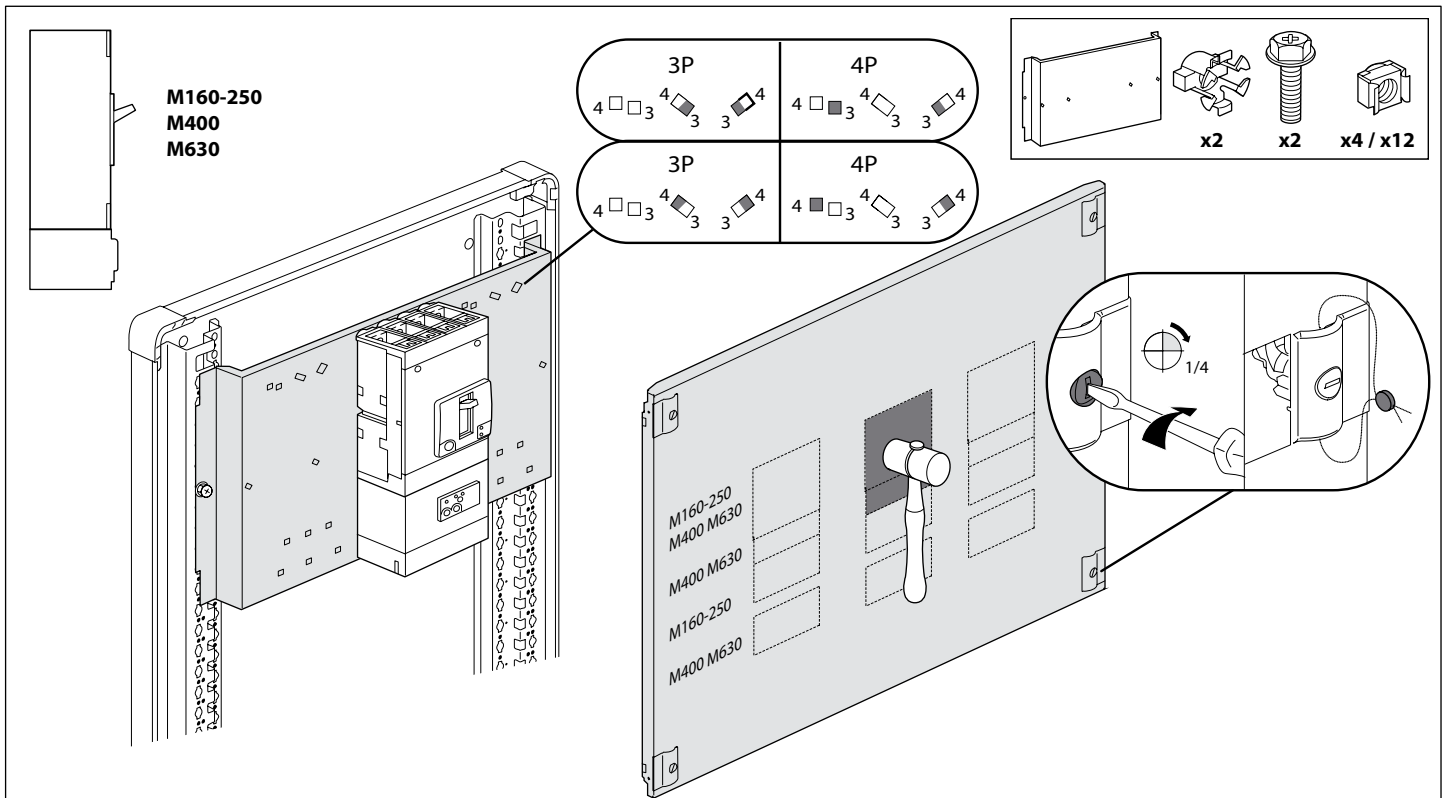
 
 
 


L = 600	9531PMEN		9533/24Q	9533/24	300 mm
	9531PMEN (+ M7X03)		9533/24Q	9533/24	300 mm
	9531MID		9533/24Q	9533/24	300 mm
L = 850	9781PMEN			9783/36	300 mm
	9531PMEN (+ M7X03)			9783/36	300 mm
	9781MID			9783/36	300 mm


M160-250
M400
M630

 

 



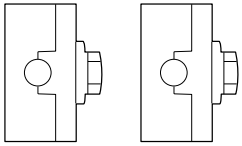
L = 600	9531P/TN	M160-250 M400 M630	9531/TNQ	9531/TN	400 mm
L = 850	9781P/TN	M160-250 M400 M630	-	9781/TN	400 mm



 
		Megatiker				
L = 600	9532P/TN	M160-250 M400 M630	x 3 x 3 x 2	9532/TNQ	9532/TN	600 mm
L = 850	9782P/TN	M160-250 M400 M630	x 3	-	9782/TN	600 mm

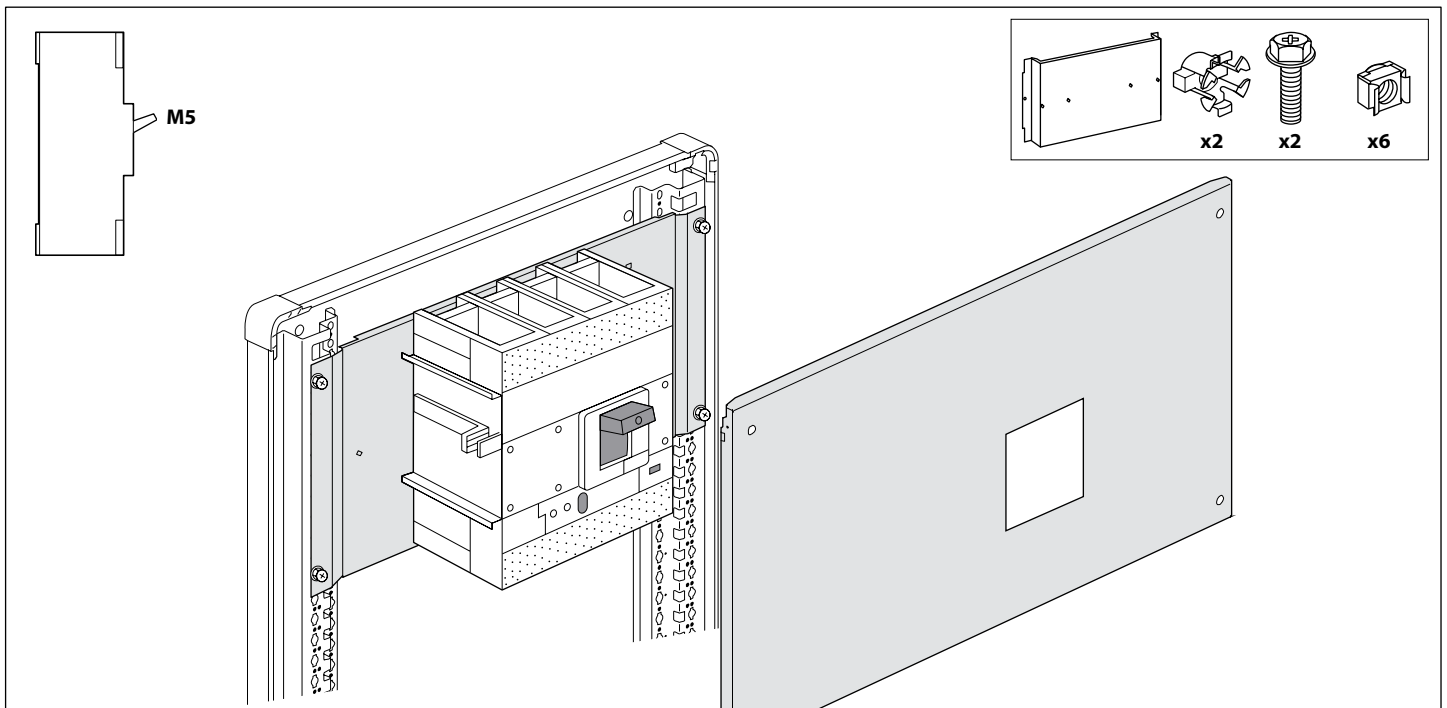



		DPX			
L = 660	9531P13	M1600	x 1	95311TS1	400 mm
L = 850	9781P13			x 2	

 


 



MW250 MW630

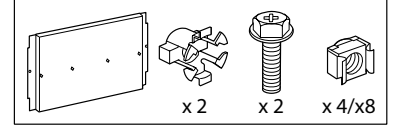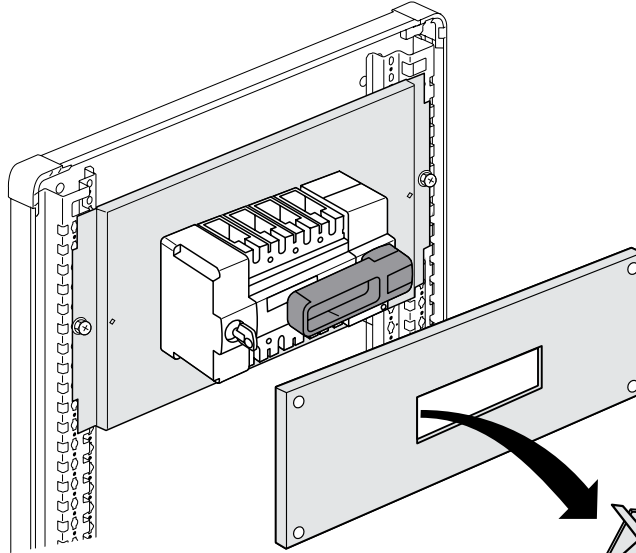

MW1600



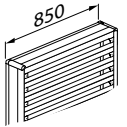		Megaswitch®			
	9561P/W 9561P/W 9561P/SW 9531P13	MW250 MW250 MW630 MW1600	x1 x2 x1 x1	9561/1W 9561/2W 9561/1W 9561SSW1	300 mm 300 mm 300 mm 400 mm
	9761P/W 9761P/W 9761P/SW 9781P13	MW250 MW250 MW630 MW1600	x1 x2 x1 x1	9761/1W 9761/2W 9761/1W 9761SSW1	300 mm 300 mm 300 mm 400 mm