

Use

Socket outlets for: Israeli standard plugs.


Range

Designation	Item
Socket 2P+E 16A 250 V a.c.	<input type="checkbox"/> RW4183
	<input type="checkbox"/> RW4183P
	<input checked="" type="checkbox"/> RG4183
	<input checked="" type="checkbox"/> RG4183P
	<input checked="" type="checkbox"/> R4183R

Color code:

White colour Black colour Red colour

Overall dimensions (mm)

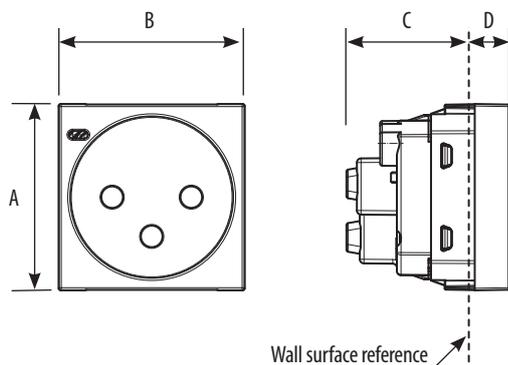

	A	B	C	D
..4183.	45.1	44.7	29.5	9.8

Connection

Terminal type: screw clamp
 Terminal capacity: 2 x 4 mm² max
 Stripping length: 11 mm
 Compatible with flexible or rigid cables

Technical characteristics

- Protection index
 (considering a complete installation, including cover plate)
 Penetration by solid bodies/liquid: IP20D

- Mechanical characteristics
 Impact test: IK 04

- Material characteristics
 Material:
 Case and Key cover: PC (Polycarbonate)
 Halogen free.

UV resistant.
 Self-extinguishing:
 850° C / 30 s for insulating parts holding live parts in place
 650° C / 30 s for other parts made of insulating materials

- Electrical characteristics
 Voltage: 250 VAC
 Current: 16 A

- Climatic characteristics
 Storage temperature: - 10° C to + 70° C
 Use temperature: - 5° C to + 35° C

Cleaning

Clean the surface with a cloth.
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.
Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC 60884-1
 SI 32 part 1.1
 Refer to e.catalogue.