

**Use**

Shutter control device : double push button with interlock sistem

**Connection**

Terminal type: screw clamp  
Terminal capacity: 2 x 2,5 mm<sup>2</sup> max  
Stripping length: 9 mm  
Compatible with flexible or rigid cables

**Range**

Designation	Item
Shutter switches double 1P (NO) + 1P (NO) with interlock	<input type="checkbox"/> N4037
	<input type="checkbox"/> NT4037
	<input type="checkbox"/> L4037

**Technical characteristics**

**- Protection index**  
(considering a complete installation, including cover plate)  
Penetration by solid bodies/liquid: IP40

**- Mechanical characteristics**  
Impact test: IK 04

**- Material characteristics**  
Case: PC (Polycarbonate)  
Key cover: ABS – ABS/PC

Halogen free.  
UV resistant.

Self-extinguishing:  
850° C / 30 s for insulating parts holding live parts in place  
650° C / 30 s for other parts made of insulating materials

**- Electrical characteristics**

Voltage: 250 V a.c.  
Current: 10 A


**- Climatic characteristics**

Storage temperature: - 10° C to + 70° C  
Use temperature: - 5° C to + 35° C

Color code:

White colour     Tech colour     Anthracite colour

**Overall dimensions (mm)**

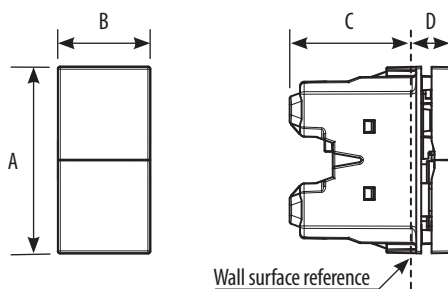

	A	B	C	D
..4037	44	22	27.5	11

**Cleaning**

Clean the surface with a cloth.  
Do not use acetone, tar-removing cleaning agents or trichloroethylene.  
**Caution: Always test before using special cleaning products.**

**Standards and approvals**

Compliance with standards IEC/EN 60669-1.  
Refer to e.catalogue.