


**Make up the room / Do no disturb**

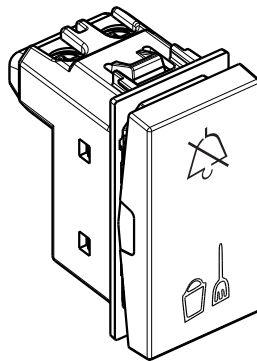

**Use**

Changeover switch for double signalling: "do not disturb" and "make up the room", for internal hotel room

**Range**

**Designation**

Changeover switch 1-0-2 with interlock and double signalling: "do not disturb" and "make up the room".  
1 module


**Item**

- RW4028HN
- RA4028HN
- RG4028HN

Color code:

- White colour
- Aluminum colour
- Black colour

**Overall dimensions (mm)**

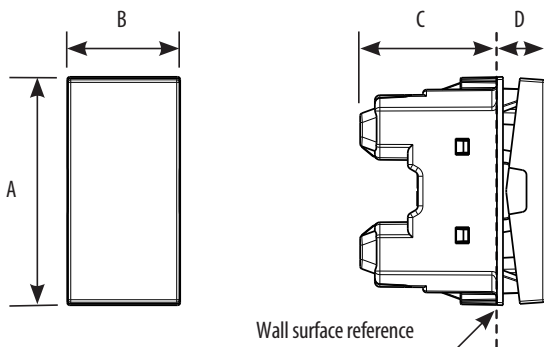

	A	B	C	D
..4028HN	45.1	22.3	25.7	10.8

**Connection**

Terminal type: screw clamp  
Terminal capacity: 2 x 2,5 mm<sup>2</sup> max  
Stripping length: 9 mm  
Compatible with flexible or rigid cables

**Technical characteristics**

**- Protection index**

(considering a complete installation, including cover plate)  
Penetration by solid bodies/liquid: IP40

**- Mechanical characteristics**

Impact test: IK 04

**- Material characteristics**

Case: PC (Polycarbonate)  
Key cover: ABS – ABS/PC

Halogen free.

UV resistant.

Self-extinguishing:

850° C / 30 s for insulating parts holding live parts in place  
650° C / 30 s for other parts made of insulating materials

**- Electrical characteristics**

Voltage: 250 V a.c.  
Current: 10 A

**- Climatic characteristics**

Storage temperature: - 10° C to + 70° C  
Use temperature: - 5° C to + 35° C

**Cleaning**

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

**Caution: Always test before using special cleaning products.**

**Standards and approvals**

Compliance with standards IEC/EN 60669-1.  
Refer to e.catalogue.